



10219018

3/4in x 7/16in - Chain sprockets ISO

2D Technical Drawing

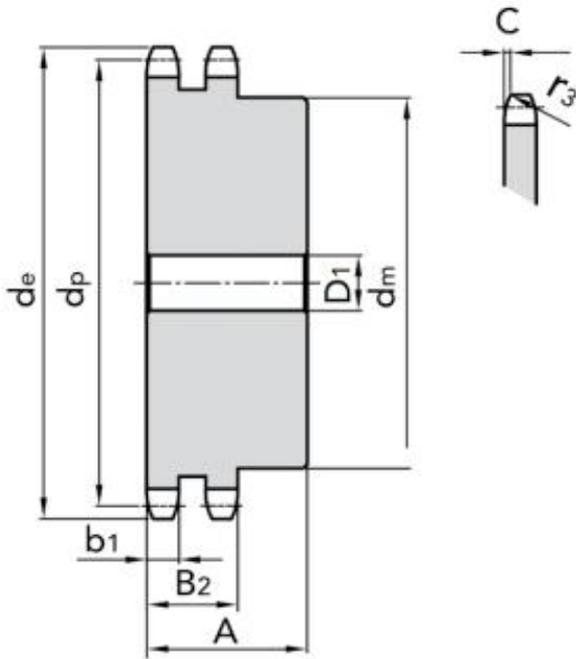

 Dynamic 3D View



Technical Specifications

Number of teeth (T)	18
de (DE) mm	117.23
dp (DP) mm	109.70
Part number (CODE)	10219018
dm (DM) mm	89
D1 (D1) mm	20
A (A) mm	50
Tooth radius r3 (R3) mm	19
Radius width C (C) mm	2
Sprockets tooth width b1 (B1) mm	10.8
Sprockets tooth width B2 (B2) mm	30.3
Weight (WEIGHT) kg	2.7
Material (MAT)	STEEL C 45