


KEMET Part Number: PHBC13-1R2A0127V
(UALP131R2A0127)

KEMET, PHBC, AC Line Filters, Normal Mode, 127 uH, 20%

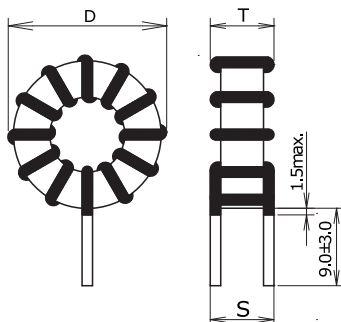

Dimensions

D	30mm MAX
T	16.2mm MAX
LL	9mm +/-3mm
S	12mm NOM

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	150
Weight:	33 g

General Information

Series:	PHBC
Style:	Through-Hole
Features:	Switching Power Supply Outlet, DC-DC Converter, Phase Compensation, Noise Solution
RoHS:	Yes
Miscellaneous:	35 (K) Temperature Rise Max.

Specifications

Inductance:	127 uH (0.1 MHz)
Inductance Tolerance:	20%
Current:	6 A
Temperature Range:	-40/+125°C
DC Resistance:	31.7 mOhms