

Features

- Ideal for precision clamping
- Secures onto a bench to enable precision working
- Can be used for mechanical and electrical items
- 75 mm jaw capacities
- High grade hardened and tempered jaws

RS PRO Bench Vice x 37.5mm 75mm x 45mm, 1.8kg

RS Stock No.: 829-6158



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

From RS PRO this mechanics bench vice is an excellent choice for using to clamp and secure all your mechanical and electrical items. The bench vice benefits from a drop forged construction which is ideal for critical holding.

General Specifications

Vice Type	Bench Vice
Applications	Workshops, Model Makers, Hobbyists, DIY enthusiasts, Garages


Mechanical Specifications

Jaw Opening	W	45mm
Jaw Width	B	75mm
Total Length	L	186mm
Anvil Size	axb	41mm x 42mm
Base Diameter	C	89
Hole Distance	D1	63
Hole Diameter	d2	7
Spindle screw	d1	8
Jaw Depth	S	37.5mm
Vice Height	H	74mm
Rotating Vice Head	Degree	360°
Mounting	Type	Bolts, Clamp
Weight	kg	1.8

Similar Products

Stock No.	Brand	Product Name	Attribute 1	Attribute 2	Attribute 3
829-6149	RS PRO	Bench Vice 30.5mm x 50mm x 35mm	Bench Vice	Jaw Width 50mm	Weight 1kg
829-6158	RS PRO	Bench Vice 37.5mm x 75mm x 45mm	Bench Vice	Jaw Width 75mm	Weight 1.8kg

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories

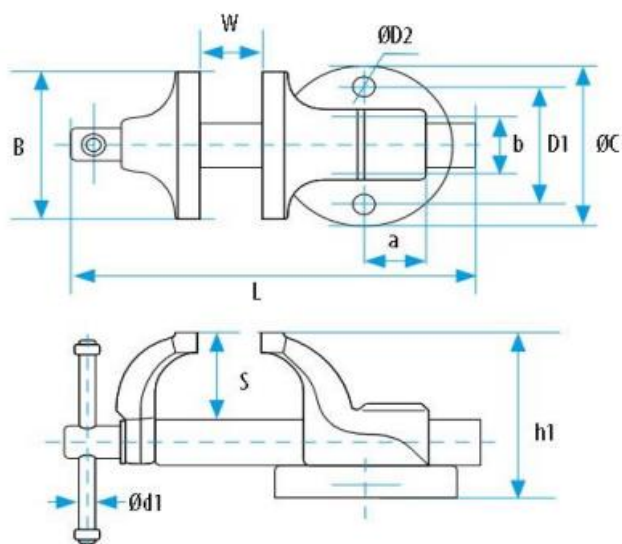

RS CODE			8296149	8296158
Size			50	75
Jaw Width	B	mm	50	75
Jaw Opening	W (max)	mm	35	45
Length	L	mm	147	186
Anvil Size	axb	mm	31x39	41x42
Base Diameter	C	mm	70	89
Hole Distance	D1	mm	48	63
Hole Diameter	D2	mm	5	7
Spindlescrew	d1 (min)	mm	6	8
Depth	S (min)	mm	30.5	37.5
Vice Height	~ h1	mm	60.7	74
Clamping Bench	~ h2	mm	45	41
Weight		kg	1	1.8