



Datasheet

Stock No: 311-9315

ENGLISH

RS Pro 2m power cord, C19 to UK Plug (BS 1363), 13 A, 250 V



Product Details:

C19 to BS1363 Plug

Brought to you under the trusted RS Brand, this power cord set is fused at 13A. With a standard UK plug adjoining a C19 socket, this power cable assembly is typically used in higher current IT applications such as power distribution units, servers and large network routers.

For mating with chassis plugs see stock no.295-8737.

Features and Benefits:

- H05W-F cable
- C19 connector rated at 16 A and 250V
- Moulded cable with strain relief at both ends.




Standards

BS 4491: 1989, BS136A, IEC 320 std C19, EN60 320 std 19



Specifications:

Connector A:	C19
Connector B:	UK Plug
Length:	2m
Current Rating:	13 A
Sheath Colour:	Black
Voltage Rating:	250 V
Connector B Angle:	Straight
Connector B Gender:	Male
Connector B Type:	BS 1363
Connector A Angle:	Straight
Connector A Type:	IEC
Connector A Gender:	Female

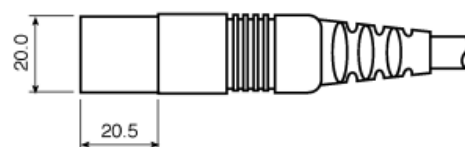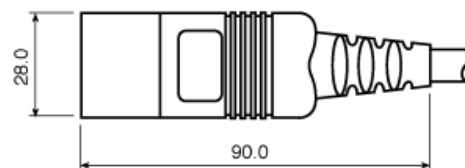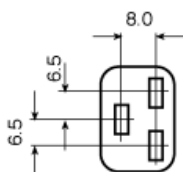

	C3	C4		C13	C14
	C5	C6		C15	C16
	C7	C8		C19	C20

IEC to BS1363 Plugs

A range of electrical appliance connecting leads, the majority of which are terminated with connectors that conform to IEC 60320. The IEC (International Electrotechnical Commission) is the international standards and conformity assessment body. The drawing illustrates the range of connector types offered within this section - The 'odd' 'C' numbers refer to a socket type connector - mains input - and the 'even' 'C' numbers refer to a plug type connector - the appliance inlet. The current rating detailed in the price table refers to the rating of the lead and plug as supplied. It does not necessarily refer to the current carrying capacity of the lead by itself.