


Universal socket strip 5-fold with switch (type G)

Item-No.: 0201x0605230b-1 (1.5 m cord) | 0201x0605230b-3 (3 m cord)

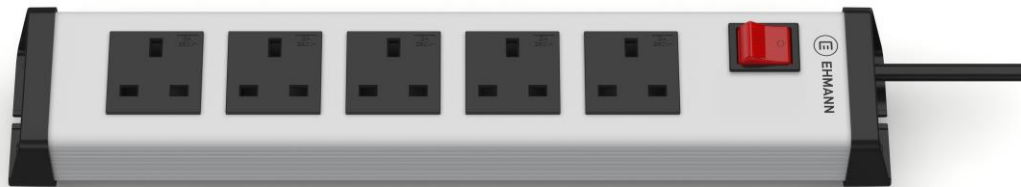


Robust plastic, grey

Built-in sockets (90° rotated), quadrangular

1.5 m power cord and angle plug (optional with 3 m power cord)


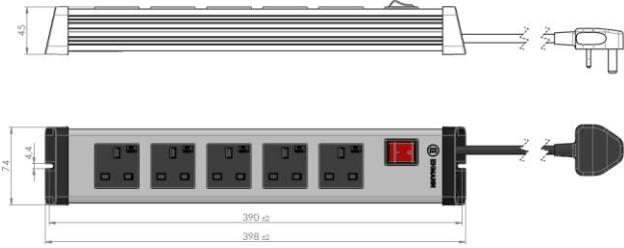
Expanded contact protection

End caps with mounting possibility

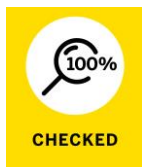

Universal socket strip 5-fold with switch (type G)

Technical data

3000 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	13 A Rated current
Power Cord: H05VV-F 3G 1.5 mm ² Plug: BP1 British Standard Type G, BS 1363/A, angled Fuse: 13A fuse according to BS 1362 Sockets: Type G Switch: 2-pole, illuminated (red) Consumption per switch: < 0,5 W Safety class: IP20		
 <p>(similar illustration)</p>		
Item-No. 0201x0605230b-1 (1,5 m cord) EAN 4012096010937 PU 10 Item-No. 0201x0605230b-3 (3 m cord) EAN 4012096013396 PU 10		398 x 74 x 45 mm Dimensions (L x W x H) 390 mm Fixing Dimension