


DX2031



Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/DC

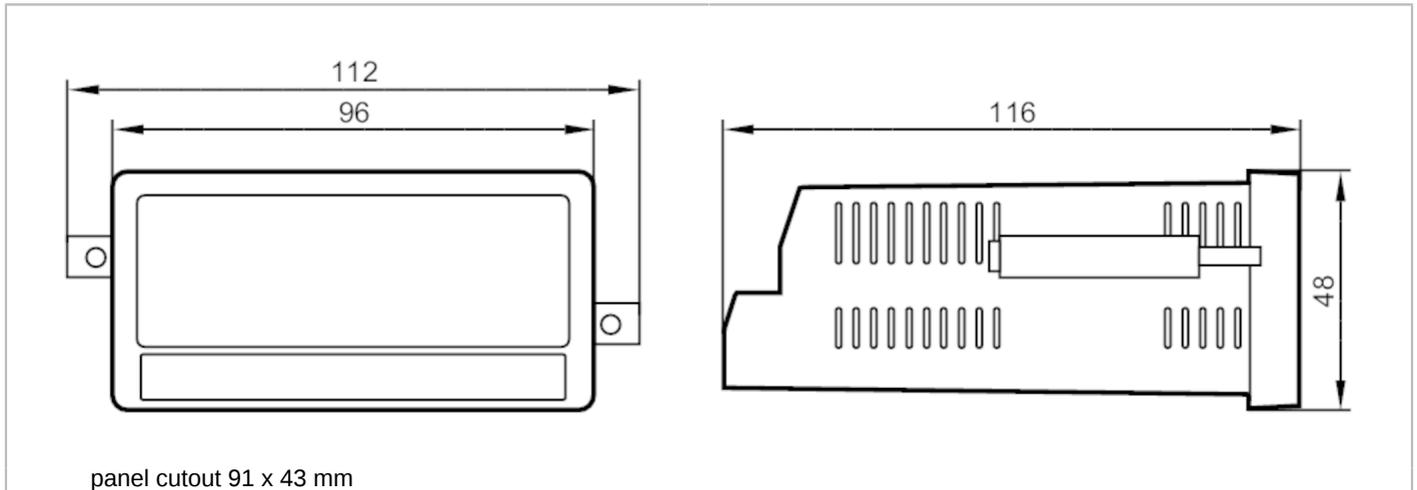

Product characteristics	
Housing	housing for panel mounting
Dimensions [mm]	48 x 112 x 116
Application	
Application	universal evaluation and display for all physical units which can be derived from pulse sequences
Electrical data	
Operating voltage [V]	18...30 DC
Current consumption [mA]	100
Inputs / outputs	
Number of inputs and outputs	Number of digital inputs: 2
Inputs	
Number of digital inputs	2
Operating conditions	
Ambient temperature [°C]	-20...60
Storage temperature [°C]	-25...70
Protection	IP 65
Protection rating terminals	IP 20
Tests / approvals	
EMC	EN 61000-6-2
	EN 61000-6-3
	EN 61000-6-4
Mechanical data	
Weight [g]	302.5
Housing	housing for panel mounting
Type of mounting	installation in panels or panel cutouts; (panel cutout: 91 x 43 mm)
Dimensions [mm]	48 x 112 x 116
Materials	Noryl UL94-V-0

DX2031



Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/DC


Displays / operating elements

Display: colour display full graphic LCD display, touch screen

Electrical connection

screw terminals:

Connection

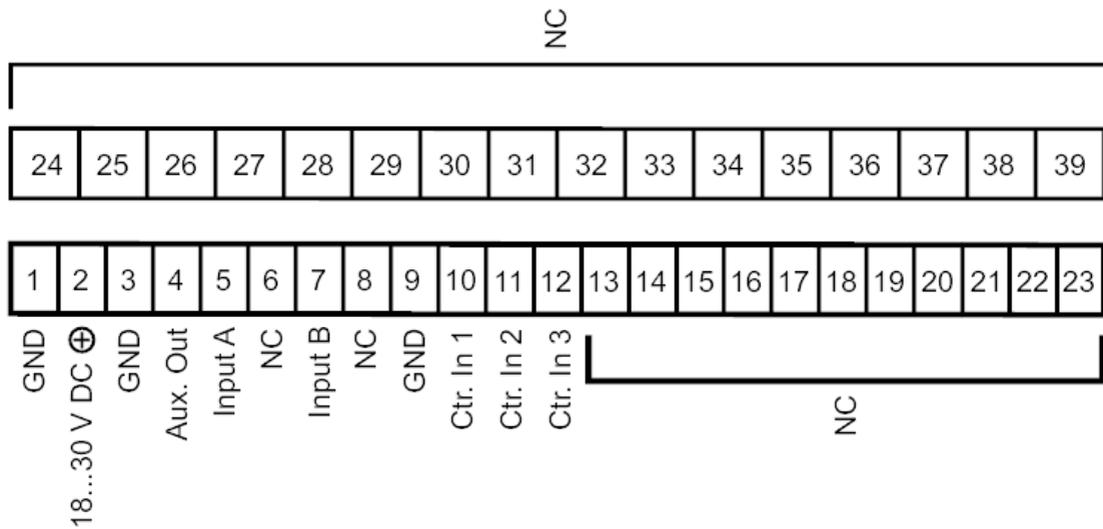

NC: not used