



Brand of NTN corporation


Technical data

BBER12UU

Flange type ball bushings



VISUAL (S)

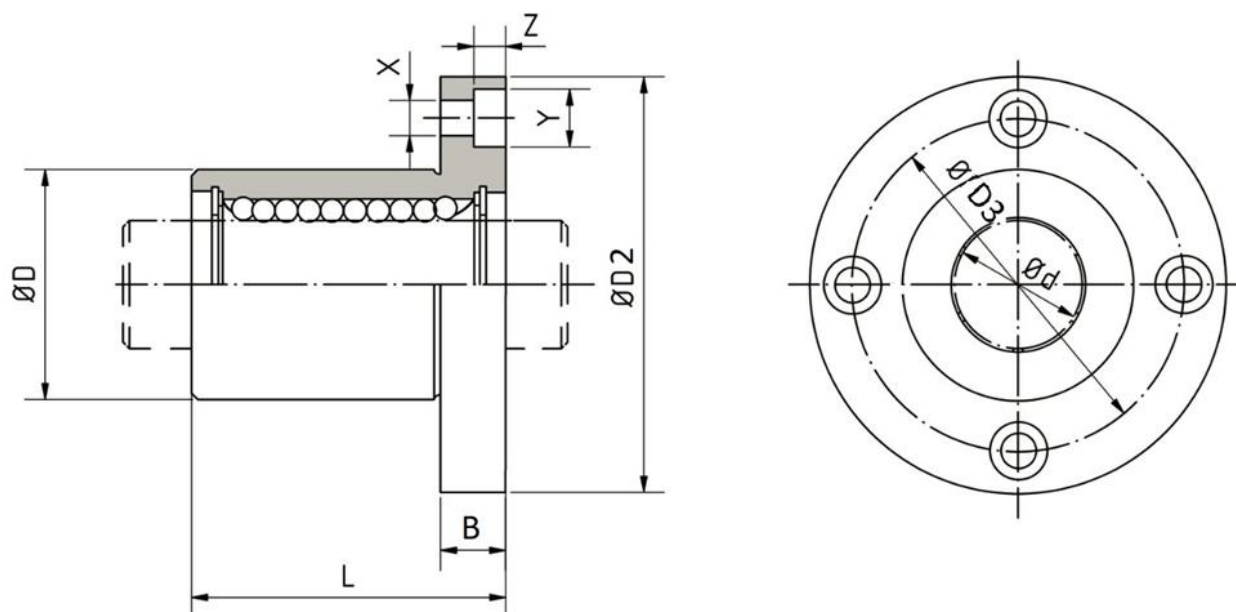

PRODUCT DEFINITION

Brand	SNR
Design type	BBER
Ball bushings category	Flange type ball bushings
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	12 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
d - Internal diameter tolerance	0,008/0
D - External diameter	22 mm
D - External diameter tolerance	0/-0,016
L - Length	32 mm
L - Length tolerance	0,3/-0,3
B - Flange width	6 mm
D2 - Diameter	42 mm
D3 - Diameter	32 mm
X	4,5 mm
Y	7,5 mm
Z	4,1 mm
Maximum eccentricity	0,012 mm
Number of ball rows	4
Mass	0,08 kg

PRODUCT PERFORMANCE	
Cmin	0,416 kN
Cmax	0,588 kN
C0min	0,784 kN
C0max	1,109 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY	
Reference	BBER12UU



ESHOPDONOTDISPLAY	
Image	BBER_1.JPG, BBER_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes
Tracepart	Oui/Yes

