



Datasheet

Fibre Optic Cable Assembly, Multi-Mode

RS Stock number 536-6535

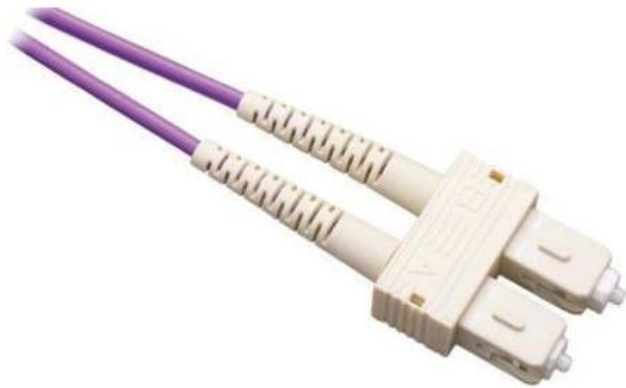

Dimensions: (mm)

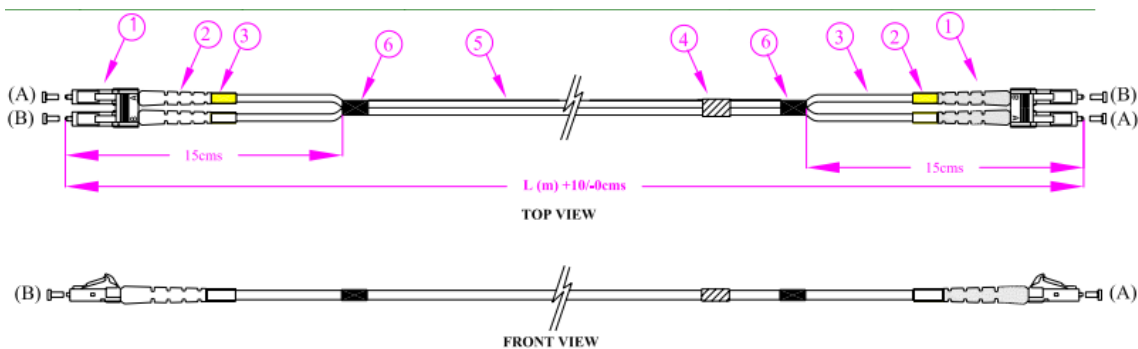

Optical Performance (IEC 61300-3-4):

Multimode (@ 1300nm)

LC : Max. IL - 0.30dB Typical: 0.20dB

Singlemode: (@1310nm and/or 1550nm)

LC : Max. IL - 0.30dB Typical: 0.20dB Return Loss: >50dB

Connector: LC clips shall be mounted on to the connector to make it duplex.

Coiling Diameter: Coiling Diameter of the patchcord shall be greater than 200mm

| Id No. | Description | Ea |
|--------|-------------------------------|-----|
| 1. | LC Duplex Connector | 2 |
| 2. | LC Boots | 4 |
| 3. | LC Heat Shrink (Yellow+White) | 2+2 |
| 4. | Identification Label | 1 |
| 5. | 1.6mm Duplex Cable (L m) | 1 |
| 6. | Black Tape | 2 |