



General characteristics

Colour	Grey
IEC degree of protection	IP66 and IP67

Mechanical features

Weight	g	1650
--------	---	------


UL technical data

UL degree of protection	NEMA 4X
-------------------------	---------

Ambient conditions

Temperature	Operating temperature	min	°C	-25
		max	°C	+70
	Storage temperature	min	°C	-40
		max	°C	+85

Dimensions

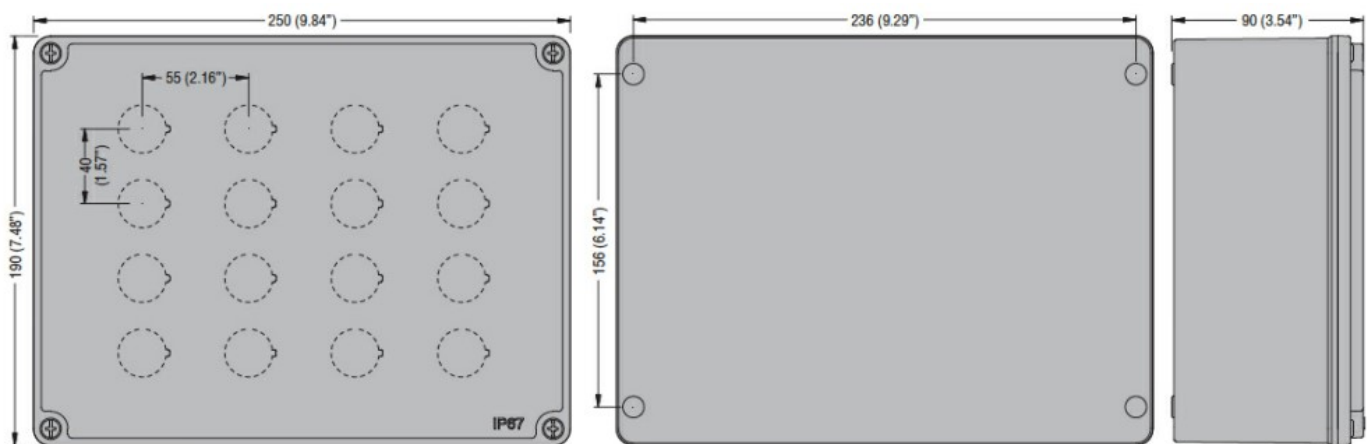

Certifications and compliance

Compliance	IEC/EN 60947-5-1
------------	------------------

Certificates	cULus EAC
--------------	--------------

ETIM classification

ETIM 8.0	EC000200 - Enclosure for control circuit devices
----------	--