




HYDNUT240-E-INCH [↗](#)

Hydraulic nut

HYDNUT..-E-INCH

Technical information

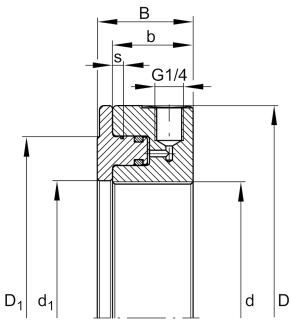

Your current product variant

Series	E-INCH	inch thread by UN/ACME standard
--------	--------	---------------------------------

Technical data

d	239.827 mm	Thread nominal diameter
---	------------	-------------------------

	237.076 mm	Thread flank diameter
--	------------	-----------------------

	UN	Thread type
--	----	-------------

	6	Number of thread convolutions per inch
--	---	--

D	330 mm	Outer Diameter
---	--------	----------------

B	53 mm	Width
---	-------	-------

b	44 mm	Width press ring
---	-------	------------------

D 1	296 mm	
-----	--------	--

d 1	242 mm	
-----	--------	--

s	10 mm	Stroke, max.
---	-------	--------------

	165.3 cm²	Piston surface
--	-----------	----------------

	500 bar	Pressure, max.
--	---------	----------------

	827 kN	Drive-up force, max.
--	--------	----------------------

≈m	17 kg	Weight
----	-------	--------

Additional information

1 pc. Hydraulic nut, 3 pcs. Clamping screws, 1 pc. Screw plug, 1 pc. Connection nipple, 3 pcs. to 5 pcs. Threaded pins, 1 pc. Hand lever, 1 pc. Replacement seal set, 1 pc. User manual	Delivery scope
--	----------------