


Data Sheet

Alarm 12C SCR PVC

Cross Section:

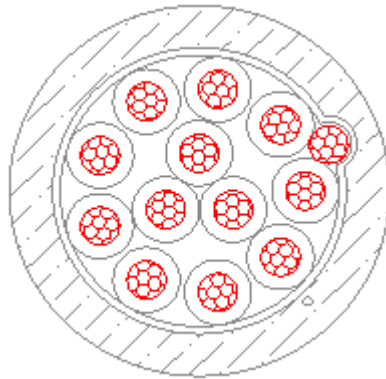

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Construction:

Conductor: Tinned Copper Claded Aluminium

Conductor Dia. (mm): TCCA0.19±0.008 x 7

Insulation: PVC

Insulation Dia. (mm): 1.00±0.08 x 12C

Al-Pet Shield

Coverage: ≥115%

Drain wire: Tinned Copper Claded Aluminium

Drain wire Dia. (mm): TCCA0.19±0.008 x 7

Nylon rip cord: 150D

Jacket: PVC

Outer Dia. (mm): 6.00±0.2

Colour:

The color of the insulation:

Red, Blue, Yellow, Black, White, Green, Brown, Orange

Grey, Pink, Violet, Light Green,

The jacket color: According to customer

Marking:

According to customer

Performance:

Electrical Characteristics:

Max. Conductor DC Resistance at 20°C (Ω/Km) :
<177

Min. Insulation DC Resistance at 20°C (MΩ
*KM) : >200