




ENGLISH

Datasheet

Stock No: 361-850

# RS Pro Black, 2491X Equipment Wire, 2.5 mm<sup>2</sup> CSA , 750 V 25 A 13 AWG, 100m

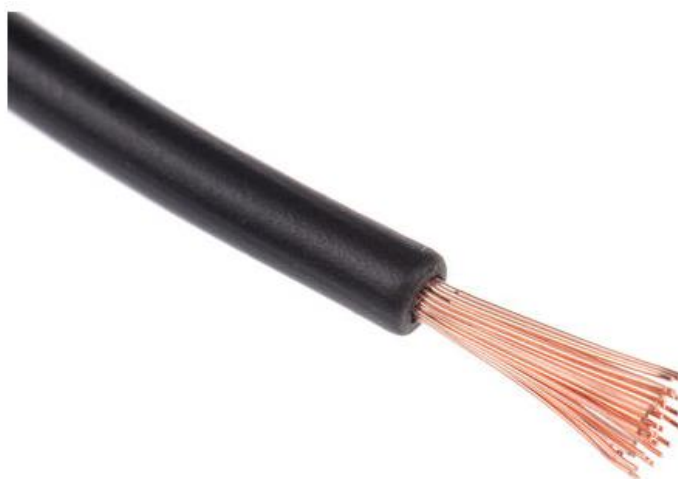

## Product Details

### 2491X

A plain copper stranded conductor covered by a PVC insulated sheath. These flexible wires are intended for use in internal wiring applications in electrical and electronic equipment, or runs within covered ducts, conduits.

#### Features & Benefits:

- \* Flexible class 5 conductors
- \* BS6004 Conductors
- \* Plain annealed copper conductors

#### Note

The RS Brand range of products has been certified by engineers as offering comparable quality to that of leading brands without the premium price tag

## Specifications

Cross Sectional Area	2.5 mm <sup>2</sup>
Sheath Colour	Black
Core Strands	50/0.25 mm
Insulation Material	PVC
Outer Diameter	4.1mm
Length	100m
Number of Strands	50
Current Rating	25 A
Voltage Rating	750 V
Size of Strands	0.25 mm
American Wire Gauge	13 AWG
Conductor Material	Annealed Copper
Type	2491X
Insulation Wall Thickness	0.8mm
Shield Type	Unshielded
European Harmonised Code	H07V-K
Cable Shape	Single Core