

Explorer-250 and Penlight

Explorer-250



- The Explorer-250 is a powerful USB rechargeable LED flashlight
- 300 metre beam and 250 lumens of light output from the advanced CREE XP-E2 LED
- The flashlight is pocket sized and robust and ultra light due to its aircraft grade aluminium body
- Three light modes to suit your needs with a 40 hour running time on the low setting
- Supplied with wriststap

Specifications Explorer-250

Light Output	250 lumens
Beam distance	300 Metre Beam
Battery	Rechargeable 3.7v Li-ion battery (18650) 2200mAh 8.14 W/h
Runtime	6hrs high 40hrs low 10 hrs strobe
LED	CREE XP-E2 cool white
Light Settings	High, low and strobe light settings
Dimensions	(L) 148mm (Dia.) 36mm
Weight	178g product weight including battery
Weight	46g weight per battery
Weather Resistance	Weather resistant to IPX4 rating
Part No.	NSEXPLORER250

- +** Optional extras:
- AC and vehicle charging adaptors
 - Nylon belt holster.



Explorer-Penlight




- The Explorer-Penlight delivers a bright 50 metre beam and has a 160 lumens output
- Advanced Cree XP-G2 R4 LED
- The flashlight is robust and ultra light due to its aircraft grade aluminium body
- Three light modes to suit your needs with a 10 hour running time on the low setting

Specifications Explorer-Penlight

Light Output	160 lumens
Beam distance	50 Metre Beam
Battery	Rechargeable 3.7v Li-ion battery (10440) 700mAh 2.59 W/h
Runtime	1.5hrs high 10hrs low 2hrs strobe
LED	CREE XP-G2 R4 cool white
Light Settings	High, low and strobe light settings
Dimensions	(L) 160mm (Dia.) 19mm
Weight	68g product weight including battery
Weight	21g weight per battery
Weather Resistance	Weather resistant to IPX4 rating
Part No.	NSEXPLORERPL

- +** Optional extras:
- AC and vehicle charging adaptors
 - Nylon belt holster.

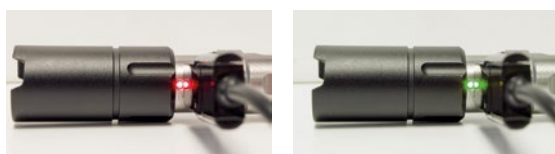

35 Charging LED indicator