


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

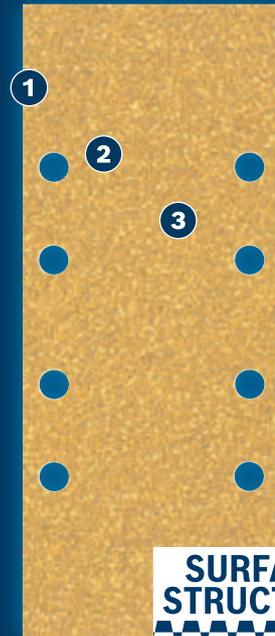

SURFACE
STRUCTURE

UP TO
2x*



* vs. Bosch C420



BOSCH

EXPERT C470 SANDPAPER



- ▶ Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- ▶ EXPERT Abrasives - the very best for all trades
- ▶ Up to 2x faster than Bosch C420 Sandpaper
- ▶ Just stick it on with hook and loop



PRODUCT PROPERTIES				ORDERING INFORMATION				Part number
Sheet dimensions mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...		
80x133	40	8 holes	C1a	10	5	542 157	2 608 900 877	
80x133	40		C0a	50	1	636 108	2 608 901 660	
80x133	60	8 holes	C1a	10	5	542 164	2 608 900 878	
80x133	60		C0a	50	1	636 115	2 608 901 661	
80x133	80	8 holes	C1a	10	5	542 171	2 608 900 879	
80x133	80		C0a	50	1	636 122	2 608 901 662	
80x133	100	8 holes	C1a	10	5	542 188	2 608 900 880	
80x133	120	8 holes	C1a	10	5	542 195	2 608 900 881	
80x133	120		C0a	50	1	636 139	2 608 901 663	
80x133	180	8 holes	C1a	10	5	542 201	2 608 900 882	
80x133	180		C0a	50	1	636 146	2 608 901 664	
80x133	240	8 holes	C1a	10	5	542 218	2 608 900 883	
80x133	320	8 holes	C1a	10	5	542 225	2 608 900 884	
80x133	400	8 holes	C1a	10	5	542 232	2 608 900 885	
93x186	40	8 holes	C1a	10	5	541 914	2 608 900 853	
93x186	40		C0a	50	1	542 737	2 608 900 935	
93x186	60	8 holes	C1a	10	5	541 921	2 608 900 854	
93x186	60		C0a	50	1	542 744	2 608 900 936	
93x186	80	8 holes	C1a	10	5	541 938	2 608 900 855	
93x186	80		C0a	50	1	542 751	2 608 900 937	
93x186	100	8 holes	C1a	10	5	542 126	2 608 900 874	
93x186	100		C0a	50	1	542 768	2 608 900 938	
93x186	120	8 holes	C1a	10	5	541 945	2 608 900 856	
93x186	120		C0a	50	1	542 775	2 608 900 939	
93x186	180	8 holes	C1a	10	5	541 952	2 608 900 857	
93x186	180		C0a	50	1	542 782	2 608 900 940	
93x186	240	8 holes	C1a	10	5	541 969	2 608 900 858	
93x186	320	8 holes	C1a	10	5	542 089	2 608 900 870	
93x186	400	8 holes	C1a	10	5	541 976	2 608 900 859	
93x186	400		C0a	50	1	542 799	2 608 900 941	
93x230	40	8 holes	C1a	10	5	541 716	2 608 900 833	
93x230	60	8 holes	C1a	10	5	541 723	2 608 900 834	
93x230	80	8 holes	C1a	10	5	541 730	2 608 900 835	
93x230	100	8 holes	C1a	10	5	542 096	2 608 900 871	
93x230	120	8 holes	C1a	10	5	541 747	2 608 900 836	
93x230	180	8 holes	C1a	10	5	541 754	2 608 900 837	
93x230	240	8 holes	C1a	10	5	541 761	2 608 900 838	
93x230	320	8 holes	C1a	10	5	542 102	2 608 900 872	
93x230	400	8 holes	C1a	10	5	541 778	2 608 900 839	



BOSCH