

A premium nitrile glove 100% individually testing providing superior standards of safety for high-risk chemical handling

- A newly developed nitrile film offers greater strength and superior chemical resistance
- Sets new standards for mechanical performance, with unrivalled abrasion resistance
- Designed to deliver optimal results in wet or dry work environments where chemical resistance is crucial
- Provides superb comfort for the wearer
- Guaranteed product quality means gloves can be used with complete confidence in dangerous situations

Industries

- Automotive
- Machinery and Equipment

Applications

- Delivery of parts to production line
- Painting or cleaning tools or robots
- Changing tools and dies



AlphaTec® Solvex®

37-900

A premium nitrile glove providing superior standards of safety for high-risk chemical handling

Previously known as: Solvex® 37-900

Key Features

- 100% sampling testing, every glove is individually subjected to a leak proof air-pressure test and checked for defects before dispatch
- Produced in an ISO 9001 certified facility
- Fully reusable with an unequaled abrasion resistance
- Out-performs all existing Nitriles in permeation tests
- Reversed lozenge finish further enhancing levels of grip
- Vend pack variant available ,not applicable for US and Canada




Vulcanization Chemical Accelerators

- Mercaptobenzothiazole
- Zinc Diethyldithiocarbamate

Only a very small number of users may be sensitive to this ingredient(s) and hence may develop irritant and/or allergic contact reactions.

Performance Standards

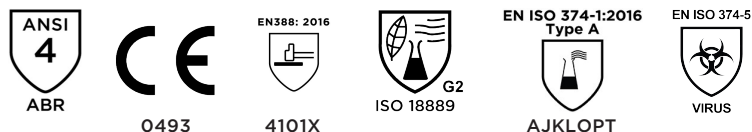

Specifications

BRAND STYLE	DESCRIPTION	SIZE	LENGTH	COLOR	PACKAGE
AlphaTec® Solvex® 37-900	Flocked, Nitrile,	7, 8, 9, 10, 11	380 / 15	Red	<ul style="list-style-type: none">• 12 pairs in a master bag; 6 master bags per carton• Vend pack variant , 1 pair per inner bag , 72 bags per carton

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada Inc.
105, rue Lauder
Cowansville (Québec)
J2K 2K8, Canada
T: 1 800 363-8340
F: 1 888 267-3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:
www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

Ansell