


# Datasheet

## E10 Filament Indicator Lamp

RS Stock number 655-9160



### Dimensions: (mm)

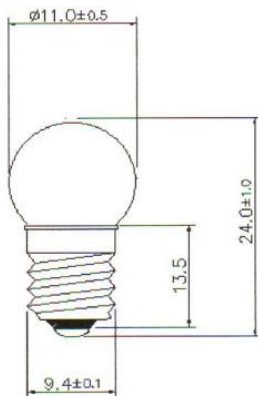

Structure	
Bulb Type	G3 ½ Clear
Bulb Diameter	11.5Max
Length	25.0Max
Base Type	E10

Design Characteristics	
Voltage	3.5V
Amperage	300mA $\pm$ 10%
Filament Type	Vacuum Type
Life Hours	1000Hours
Luminous Flux	6.0Lm $\pm$ 20%