


PACTEC® Plastic Enclosures

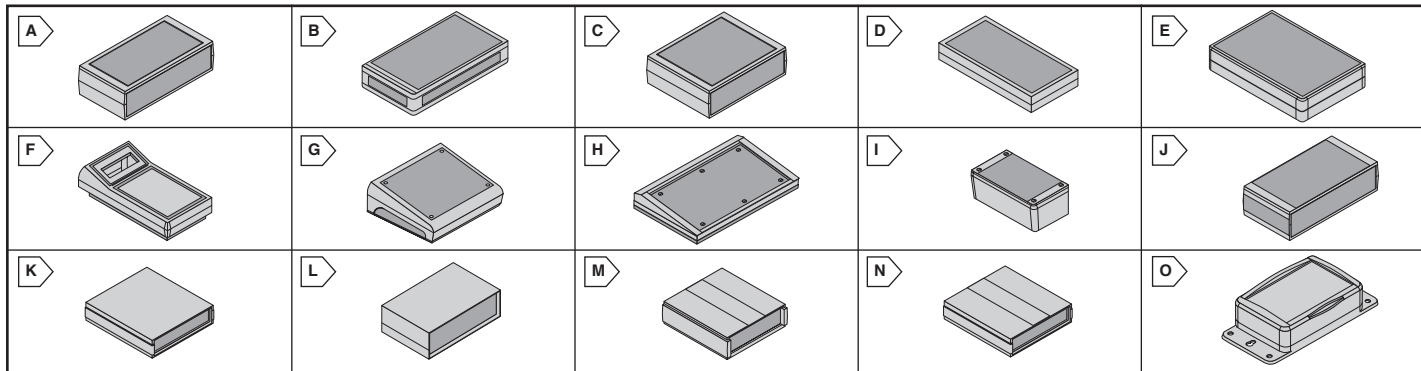

PACITEC® HANDHELD ENCLOSURES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	PacTec Model No.	Pactec Part Number		Dimensions: in.					Price Each			
Black	Bone			Black	Bone	L	W	H	PC Board		1	10	25	50
616-71971-510-000	616-71972-510-039	A	JM-12IE	71971-510-000	71972-510-039	2.40	1.60	0.80	1.90	1.10	2.09	1.99	1.89	1.78
616-69313-510-000	616-69316-510-039	A	JM-22	69313-510-000	69316-510-039	2.40	2.20	1.00	1.90	1.70	2.13	2.03	1.92	1.83
616-71867-510-000	616-71868-510-039	A	JM-42	71867-510-000	71868-510-039	3.80	2.40	1.00	3.30	1.90	4.73	4.52	4.29	4.06
616-61980-510-000	616-61985-510-039	B	HM-9VB	61980-510-000	61985-510-039	3.80	2.40	1.00	3.10	1.90	4.01	3.82	3.61	3.43
616-62558-510-000	616-62562-510-039	C	HML	62558-510-000	62562-510-039	4.60	2.70	0.90	4.10	2.20	4.91	4.68	4.43	4.22
616-62578-510-000	616-62582-510-039	C	HML-9VB	62578-510-000	62582-510-039	4.60	2.70	1.00	4.10	2.20	5.64	5.33	5.09	4.82
616-60616-510-000	616-61989-510-039	D	HP	60616-510-000	61989-510-039	5.70	3.60	1.10	5.20	3.10	6.10	5.79	5.50	5.22
616-60620-510-000	616-62006-510-039	D	HP-9VB	60620-510-000	62006-510-039	5.70	3.60	1.20	5.20	3.10	7.50	7.14	6.77	6.41
616-60624-510-000	616-62040-510-039	E	HPL	60624-510-000	62040-510-039	7.50	4.10	1.10	7.00	3.60	8.44	8.03	7.61	7.25
616-60628-510-000	616-62057-510-039	E	HPL-9VB	60628-510-000	62057-510-039	7.50	4.10	1.20	7.00	3.60	8.98	8.54	8.10	7.70
616-60607-510-000	616-62016-510-039	F	HPS	60607-510-000	62016-510-039	5.70	3.60	1.10	5.20	3.10	7.12	6.76	6.40	6.10
616-60611-510-000	616-62036-510-039	F	HPS-9VB	60611-510-000	62036-510-039	5.70	3.60	1.30	5.20	3.10	8.20	7.77	7.41	7.00

PACITEC® KEYBOARD ENCLOSURES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	PacTec Model No.	Pactec Part Number		Dimensions: in.					Price Each			
Black	Bone			Black	Bone	L	W	H	PC Board		1	10	25	50
616-82399-510-000	616-82399-510-039	G	PT-8	82399-510-000	82399-510-039	6.60	8.90	2.70	6.10	8.40	30.54	29.05	27.56	26.23
616-82404-510-000	616-82404-510-039	G	PT-10	82404-510-000	82404-510-039	7.90	11.00	3.00	7.40	10.50	36.65	33.23	31.52	30.01
616-73700-510-000	616-73701-510-039	H	KEU-5LP	73700-510-000	73701-510-039	5.40	5.40	1.50	4.90	4.90	8.98	8.53	8.09	7.70
616-63100-510-000	616-63104-510-039	H	KEU-7	63100-510-000	63104-510-039	5.10	7.10	3.00	4.60	6.60	15.73	14.95	14.20	13.49
616-62291-510-000	616-62290-510-039	H	KEU-10	62291-510-000	62290-510-039	8.10	10.10	4.00	7.60	9.60	19.74	18.75	17.82	16.92
616-72556-510-000	616-72557-510-039	H	KEU-10LP	72556-510-000	72557-510-039	8.10	10.10	2.10	7.60	9.60	15.99	15.18	14.42	13.70

PACITEC® UTILITY ENCLOSURES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	PacTec Model No.	Pactec Part Number		Dimensions: in.					Price Each			
Black	Bone			Black	Bone	L	W	H	PC Board		1	10	25	50
616-74921-510-028	616-74922-510-060	I	FLX-2535	74921-510-028	74922-510-060	3.50	2.50	1.10	3.00	2.00	5.63	5.35	5.11	4.82
616-74980-510-028	616-74981-510-060	I	FLX-4624	74980-510-028	74981-510-060	4.60	2.40	1.30	4.10	1.90	7.95	7.15	6.50	6.15
616-74923-510-028	616-74924-510-060	I	FLXT-2535	74923-510-028	74924-510-060	3.50	2.50	1.10	3.00	2.00	6.29	6.02	5.72	5.43
616-74982-510-028	616-74983-510-060	I	FLXT-4624	74982-510-028	74983-510-060	4.60	2.40	1.30	4.10	1.90	10.61	10.10	9.64	9.11

PACITEC® DESKTOP ENCLOSURES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	PacTec Model No.	Pactec Part Number		Dimensions: in.					Price Each			
Black	Bone			Black	Bone	L	W	H	PC Board		1	10	25	50
616-75054-510-000	616-75053-510-039	J	LH43-100	75054-510-000	75053-510-039	3.10	4.50	1.20	2.60	4.00	5.88	5.58	5.30	5.03
616-75815-510-000	616-75816-510-039	J	LH43-200	75815-510-000	75816-510-039	3.10	4.50	1.70	2.60	4.00	6.47	6.15	5.84	5.56
616-79160-510-000	616-79160-510-039	J	LH45-175	79160-510-000	79160-510-039	4.70	4.10	1.70	4.20	3.60	7.69	7.31	6.94	6.62
616-71886-510-000	616-71887-510-039	J	LH55-130	71886-510-000	71887-510-039	5.10	5.10	1.50	4.60	4.60	9.17	8.71	8.28	7.86
616-71988-510-000	616-71989-510-039	J	LH55-200	71988-510-000	71989-510-039	5.10	5.10	2.20	4.60	4.60	10.87	10.29	9.82	9.29
616-74216-510-000	616-74217-510-039	J	LH57-130	74216-510-000	74217-510-039	7.20	5.50	1.50	6.70	5.00	10.74	10.16	9.69	9.16
616-71894-510-000	616-71895-510-039	J	LH64-130	71894-510-000	71895-510-039	4.20	6.10	1.50	3.70	5.60	7.80	7.41	7.01	6.69
616-71902-510-000	616-71903-510-039	J	LH84-130	71902-510-000	71903-510-039	4.20	8.10	1.50	3.70	7.60	11.50	10.95	10.44	9.88
616-74208-510-000	616-74209-510-039	J	LH96-130	74208-510-000	74209-510-039	6.20	9.10	1.50	5.70	8.60	13.76	13.09	12.42	11.81
616-74212-510-000	616-74213-510-039	J	LH96-200	74212-510-000	74213-510-039	6.20	9.10	2.20	5.70	8.60	15.73	15.01	14.24	13.48
616-76445-510-000	616-76445-510-039	J	LH129-250	76445-510-000	76445-510-039	9.30	11.10	2.20	8.80	10.60	19.50	18.55	17.60	16.75
616-71913-510-000	616-71914-510-039	K	CM3-100	71913-510-000	71914-510-039	5.20	3.30	1.20	4.70	2.80	8.28	7.87	7.47	7.11
616-63000-510-000	616-62999-510-039	K	CM3-150	63000-510-000	62999-510-039	5.20	3.30	1.70	4.70	2.80	8.95	8.48	8.08	7.70
616-63050-510-000	616-63049-510-039	K	CM5-125	63050-510-000	63049-510-039	5.20	5.10	1.50	4.70	4.60	10.21	9.28	8.58	8.12
616-64025-510-000	616-61956-510-039	K	CM5-200	64025-510-000	61956-510-039	5.20	5.10	2.20	4.70	4.60	9.43	8.93	8.52	8.06
616-71921-510-000	616-71922-510-039	K	CM6-150	71921-510-000	71922-510-039	6.20	6.10	1.70	5.70	5.60	12.35	11.75	11.14	10.61
616-63075-510-000	616-63074-510-039	K	CM6-225	63075-510-000	63074-510-039	6.20	6.10	2.50	5.70	5.60	14.02	13.35	12.66	12.05
616-64000-510-000	616-63999-510-039	K	CM6-300	64000-510-000	63999-510-039	6.20	6.10	3.20	5.70	5.60	15.26	14.51	13.77	13.11
616-63240-510-000	616-63244-510-039	K	CM69-180	63240-510-000	63244-510-039	9.50	6.30	1.90	9.00	5.80	17.53	16.67	15.82	15.05
616-63270-510-000	616-63274-510-039	K	CM69-240	63270-510-000	63274-510-039	9.50	6.30	2.50	9.00	5.80	18.31	17.42	16.52	15.72
616-63025-510-000	616-63024-510-039	K	CM86-225	63025-510-000	63024-510-039	6.20	8.10	2.50	5.70	7.60	17.39	16.54	15.78	14.93
616-72500-510-000	616-72494-510-039	L	DM-2	72500-510-000	72494-510-039	11.40	10.40	2.30	10.90	9.90	31.41	29.87	28.33	26.97
616-72501-510-000	616-72495-510-039	L	DM-3	72501-510-000	72495-510-039	11.40	10.40	3.30	10.90	9.90	32.04	30.47	29.08	27.51
616-72502-510-000	616-72496-510-039	L	DM-4	72502-510-000	72496-510-039	11.40	10.40	4.30	10.90	9.90	32.67	31.07	29.47	28.05
616-61000-510-000	616-61866-510-039	M	C-23	61000-510-000	61866-510-039	9.20	8.50	2.4-3.6	8.70	8.00	27.94	26.54	25.21	23.96
616-63210-510-000	616-63214-510-039	N	CF-275	63210-510-000	63214-510-039	9.10	8.30	3.10	8.60	7.80	22.93	21.71	20.71	19.60

PACITEC® OUTDOOR/IP RATED ENCLOSURES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	PacTec Model No.	Pactec Part Number		Dimensions: in.					Price Each			
Gray	---			Gray	---	L	W	H	PC Board		1	10	25	50
OD Series														
616-82365-510-332	---	O	OD-45	82365-510-332	---	5.10	3.10	1.50	4.60	2.60	28.25	26.94	25.50	24.33
616-82428-510-332	---	O	OD-56	82428-510-332	---	6.00	5.00	1.50	5.50	4.50	26.43	25.14	23.99	22.70