


Technical data sheet

Article number:
156-00948

T50ROSEC4A

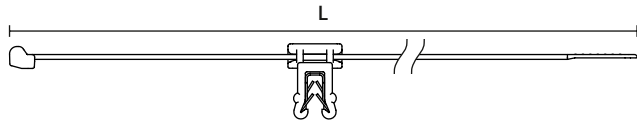

Product Group	2-piece fixing ties for edges
Product Family	EdgeClip-Series, 1.0 - 3.0 mm, top fixing
Material	Polyamide 6.6, UV-resistant (PA66W)
Colour	Black (BK)
Application Tool	ProCut 9 no battery, MK3PNSP2, EVOcut, MK7P, MK10-SB, MK20, EVO7, EVO7SP, EVO7i, EVO7iSP, EVO9, EVO9SP, EVO9i, EVO9iSP
Bundle Ø max.	45.0 mm
Bundle Ø min.	4.0 mm
Fixation Method	EdgeClip, top, assembled, 2 piece
Flammability	UL 94 V2
Height (H)	1.3 mm
Length (L)	200 mm
Length (L2)	14.0 mm
Min.Tensile Strength	225 N
Operating Temperature	-40 °C to +85 °C
Package Content packed in	bag
Pack Cont.	100 pcs.
Panel Thickness	3.00 mm
Panel Thickness max.	1.0 - 3.0 mm
Panel Thickness min. (metric)	1.00 mm
ROHS compliant	Yes
Thickness (T)	1.2 mm
Variant	Outside Serrated
Width (W)	4.6 mm

