


Datasheet

Universal Voltage 100-277V Electronic Ballasts for T5/T8/TC-L Lamps

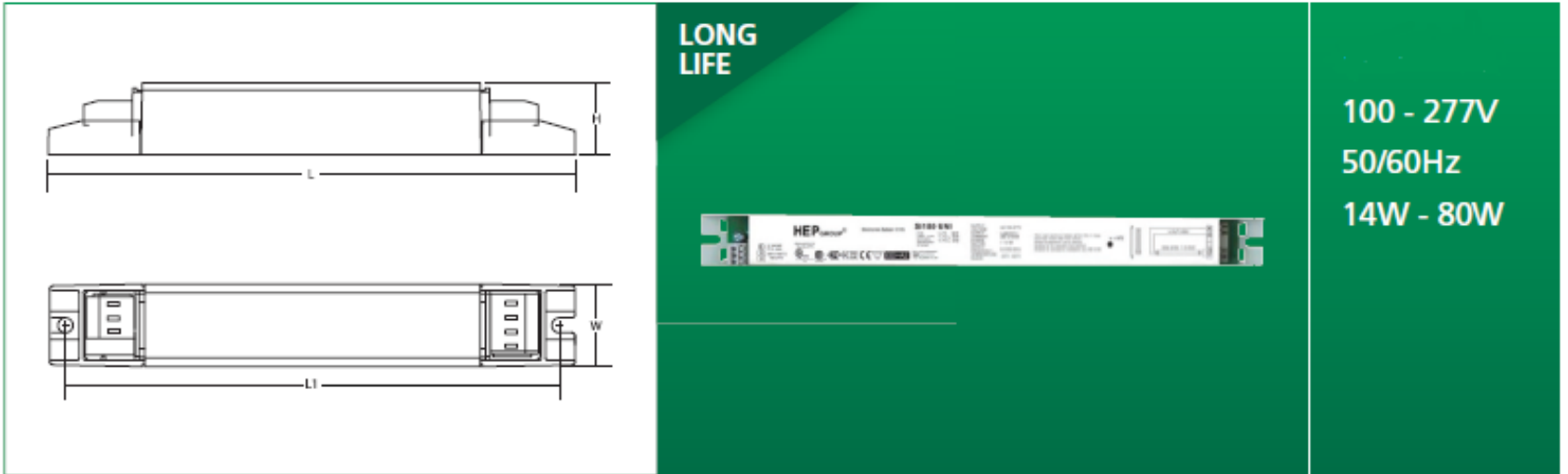

- 80,000 hour ballast warranty
- Optimal operation at universal rated voltages between 100-277V AC and 160-300V DC
- Low stock holding costs due to one ballast type operating several wattage and lamp types
- Automatic identification of lamp type
- Lamp warm start within <1 second
- Auto-cut off protection at lamp end-of-life
- Auto-restart after replacement of defective lamp
- Short circuit protection

- Open circuit safety
- High frequency lamp operation (over 45kHz)
- ENEC KEMA certified according to EN60929:2006, EN61347-1:2008, EN61347-2-3:2001+A1:2004+A2:2006
- EMC compliance with EN55015:2006A1+2007 (RFI suppression), EN61000-3-2 (Mains Harmonics), EN61547 (Immunity)
- Manufactured using environmentally friendly components complying to RoHS
- Long life – 80,000 hours

Ballast Reference	Lamp	No. of Lamps	Cap	ta °C	tc °C	EEI Index	λ	Dimensions mm			
								W	H	L	L ₁
778-5313	T5 14,21,28,35W	1	G5	-25 +60	75	2	0.98	30	26	285	268.5
778-5326	T5 H0 24,39W	1	G5	-25 +60	75	2	0.98	30	26	285	268.5
778-5323	T5 H0 54W	1	G5	-25 +60	75	2	0.98	30	26	285	268.5