
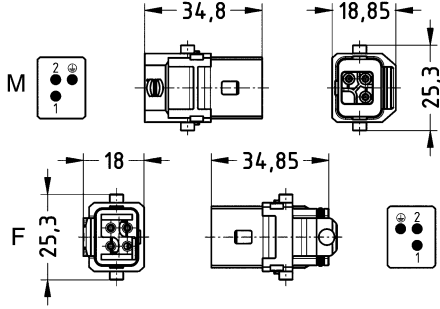

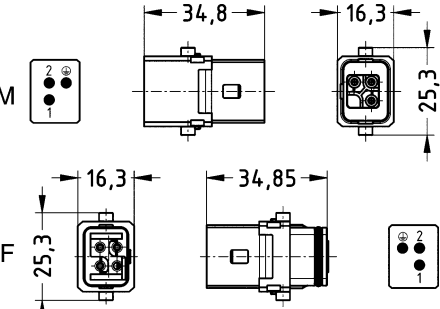

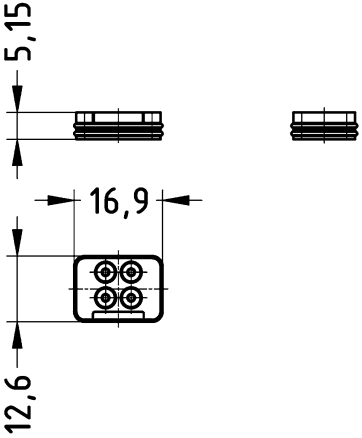


Identification	Conductor cross-section (mm ²)	Part number		Drawing (dimensions in mm)
		Male	Female	
<p>Han® 1 A , Screw termination, Snap-in latches , Contact surface: Silver plated</p>  <p>Order separately the single wire seal or the hoods/housings for an IP65 performance.</p>	0,75 ... 1,5	09 10 002 2600	09 10 002 2700	 <p>Tightening torque 0.25 Nm</p>
<p>Han® 1 A , Screw termination, Single locking lever , Contact surface: Silver plated</p>  <p>Order separately the single wire seal or the hoods/housings for an IP65 performance. Please order locking lever separately.</p>	0,75 ... 1,5	09 10 002 2605	09 10 002 2705	 <p>Tightening torque 0.25 Nm</p>
<p>Single wire seal, Silicone, for 4 contacts</p> 		09 10 004 9900	09 10 004 9900	

Han
1 A