




LED G9 Glass DIM 2.2W (25W) 250lm 827 Clear

Article number: 145773

BAI LED Compact G9 Glass 230-240V 2.2W 250lm (25W) 2700K Dimmable Clear 16x63mm Capsule LED-lamp

The LED compact series consists of lamps that are ideal as replacements for the 230V halogen lamps with G9 base due to their compact design. LED technology in a traditional halogen capsule for the same look & feel. Ambient temperature range: -20°C to +40°C.

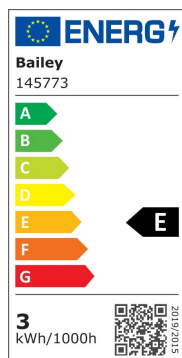

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED G9 Glass DIM 2.2W (25W) 250lm 827 Clear
Brand	Bailey
Productseries	LED Capsule MV
Producttype	G9 827 CL

ETIM specifications

Socket	G9
Luminous flux [lm]	250 - 250
Nominal voltage [V]	220 - 240
Lamp power [W]	2.2 - 2.2
Colour temperature [K]	2700 - 2700
Diameter [mm]	16
Length [mm]	63
Dimmable	Yes
Lamp shape	Other
Beam angle [°]	360 - 360
Colour	White
Type of glass/cover	Clear
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	250
Power factor	0.7
Lamp efficacy [lm/W]	113
Nominal current [mA]	12 - 12
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	3
Remote operation possible	No
With movement sensor	No
With remote control	No
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No
Dimming Bluetooth	No

Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	E
With twilight switch	No
Material of light bulb	Glass

Alternative articles




145241
LED FIL G9 DIM 3.5W (27W)
280lm 922 Clear




146033
LED G9 Glass DIM 2.2W (25W)
220lm 822 Clear

Complementary articles

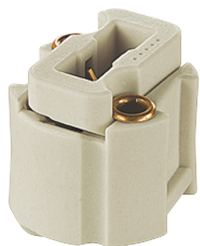

140268
BJB 25.830.1000.00 G9
Lampholder Ceramic

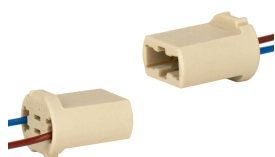

141211
Lampholder G9 6A 250V T250°C
250mm