

NEW

prevoS1 blow gun with composite nozzle



Technical characteristics

Profile:

Max operating pressure: 12 bar

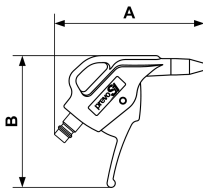
Temperature: -15°C to +70°C

Construction: Polyamide composite body

Highlight: Compact

Connection: Built-in adaptor

prevoS1 coupler sold separately: ESI 07

| | A (mm) | B (mm) | Blowing force (at 6 bar (g)) | Dynamic pressure (at 10 mm at 6 bar (bar)) | Air consumption (at 6 bar (Nm ³ /h)) | Sound level (at 6 bar (dBA)) | Parts Numbers |
|------------------------------------------------------------------------------------|-----------|-----------|---------------------------------|-----------------------------------------------|----------------------------------------------------|---------------------------------|------------------|
|  | 111 | 97 | 286 | 2.5 | 14 | 85 | EBG 07PRE |