


Drive shaft adapter DARF-Q13-12

Part number: 8200997

FESTO

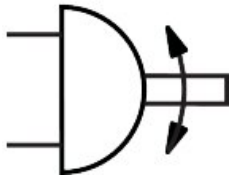

Data sheet

 General operating condition

Feature	Value
Size	12
Mounting position	Any
For piston diameter	Ø12
Design	Drive shaft adapter
Symbol	00991265
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-C1-L
Suitability for the production of Li-ion batteries	Suitable for battery production with reduced Cu/Zn/Ni values (F1a)
Cleanroom suitability, measured according to ISO 14644-14	Class 9 according to ISO 14644-1
Storage temperature	-20 °C ... 60 °C
Ambient temperature	0 °C ... 60 °C
Max. bending moment	2 Nm
Max. axial load static	80 N
Product weight	50 g
Type of mounting	Via through-hole and centring sleeve
Note on materials	RoHS compliant
Drive shaft adapter material	Tempered steel