


KEMET, PLT, Pulse Transformers, PLT

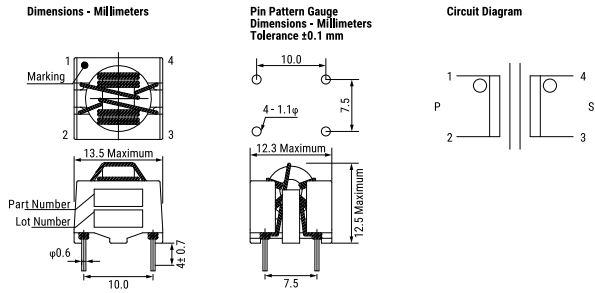

General Information	
<b>Series:</b>	PLT
<b>Style:</b>	Through-Hole
<b>Features:</b>	Proprietary Ferrite Material, Flat Insertion Loss Characteristics, UL94 V-0 Flame Retardant Rated Base
<b>RoHS:</b>	Yes
<b>Qualifications:</b>	UL94V-0
<b>Miscellaneous:</b>	Operating Temperature Range Includes Self-temperature Rise

Dimensions	
<b>L</b>	13.5mm MAX
<b>W</b>	12.3mm MAX
<b>H</b>	12.5mm MAX
<b>LL</b>	4mm +/-0.7mm
<b>S</b>	10mm NOM

Specifications	
<b>Voltage AC:</b>	264 VAC Maximum, 3600 VAC (Dielectric, 2 Seconds Between Coil and Coil, No Abnormality)
<b>Temperature Range:</b>	-25/+100°C
<b>DC Resistance:</b>	55 mOhms

Packaging Specifications	
<b>Packaging:</b>	Bulk, Box
<b>Packaging Quantity:</b>	280
<b>Weight:</b>	1.8 g