


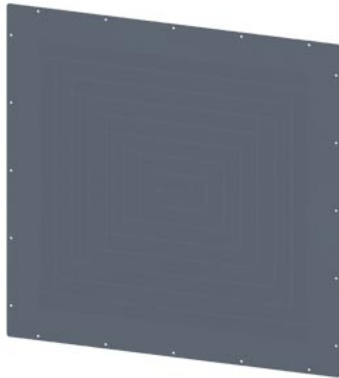

SIVACON, Roof, with Ventilation openings with Ventilation openings IP40, W: 1000 mm, T: 1000 mm, zinc-plated

Model		
product brand name	SIVACON	
product designation	top plate	
design of the product	With ventilation openings	
design of the surface	zinc plated	
design of the product EMC version	No	
Protection class		
protection class IP	IP40	
Suitability		
suitability for use for outside use	No	
Product details		
product component		
• cable entry	No	
• ventilation	Yes	
Mechanical Design		
width	1 000 mm	
depth	1 000 mm	
ventilation cross section outlet can be used	1 531 cm²	
net weight	12.1 kg	
material	steel	
Approvals Certificates		
General Product Approval		Test Certificates
		other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)

Siemens
EcoTech



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1000-2UD30-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1000-2UD30-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1000-2UD30-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

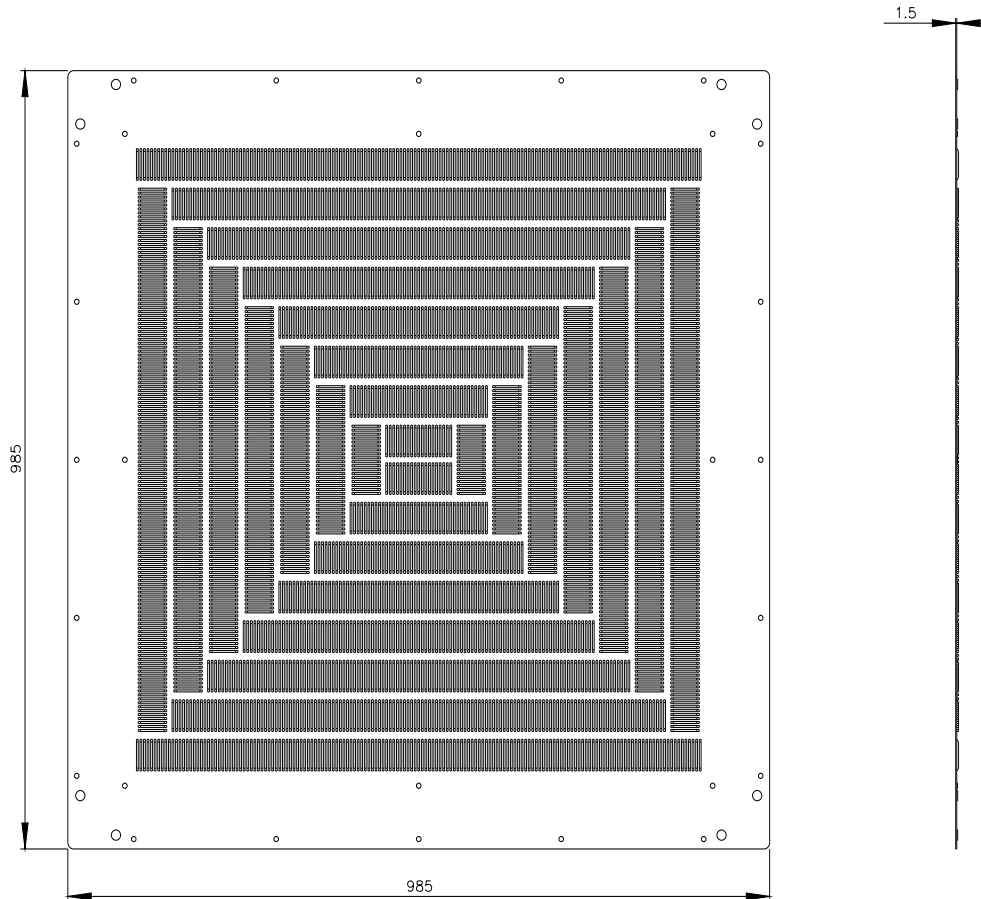

last modified:

1/16/2025 

