

# Intashield IS-300

## 1 PORT RS232/ 1 PORT LPT

### ■ PRODUCT INFORMATION

#### ■ OPERATING SYSTEMS:

Windows 2000, Windows XP,  
Windows Server 2003

#### ■ PRODUCT FEATURES:

- 1x9 pin, D type RS232 Serial Port
- 1 LPT Port on adapter cable
- PCI Bus - Fully Plug & Play
- PCI 2.3 Compliant
- 16 Byte transmit and receive FIFO
- Supports both 3.3V / 5V standards
- Drivers for all popular operating systems
- Test software provided
- Install guide, FAQ and other support documents provided


#### ■ SPECIFICATIONS:

- Serial Ports: 1 RS232
- Parallel Ports: 1
- UART: 16550
- Speed: 115,200 maximum baud rate
- Data Bits: 5, 6, 7 or 8
- Stop Bits: 1 or 2
- Parity: Odd, even, none, mark or space
- FIFO Size: 16 byte
- Bus type: 32-bit PCI
- IRQs: Plug and play -  
Shared interrupts for all ports



- This card provides 1 industry standard 9 pin RS232 serial COM port in a single PCI slot. By adding the LPT adapter cable, a parallel printer port becomes available.

As PCI is fully Plug & Play compatible the operating system or BIOS automatically configures the card ensuring conflict free installation.

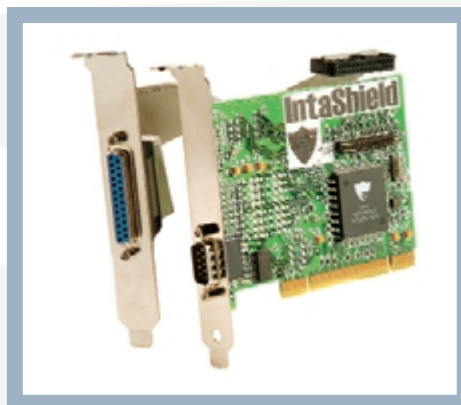

- **INTASHIELD IS-300**  
**1 PORT RS232/ 1 PORT LPT**  
PRODUCT CODE: IS-300 Version 2