

# Datasheet


705-1229  
Electronic Outside Micrometer  
Specification:0-25mm  
Resolution:0.001mm  
Accuracy:  $\pm 0.002\text{mm}$



## Feature:

- Easy operation.
- Display data is origin data of absolute measurement after changing battery.
- Painted frame. Carbide measuring faces.
- Ratchet friction thimble.
- Criterion: DIN863/1,DIN40050/IEC529.
- Resolution: 0.001mm(Metric); 0.00005"(Inch).

	Single function key	Double function keys
Power ON/OFF	✓	✓
Abs. and inc. conversion	✗	✓
Metric/inch conversion	✗	✓
Data output	✗	✗
Origin data set	✓	✓
Battery	SR44	SR44
Auto power off	✓	✓
Power consumption	<35μA	<35μA

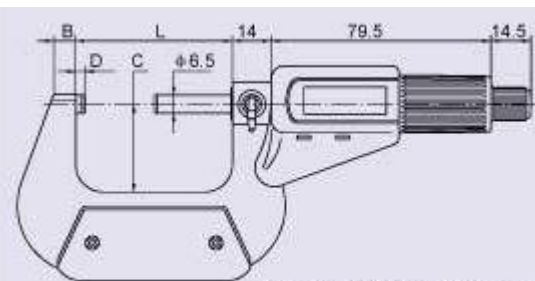

Ratchet friction thimble

Range		C	L	B	D
Metric	Inch				
0-25mm	0-1"	24mm	32mm	6mm	3.0mm