



## PUSH GIRDER TROLLEYS

- Capacities 500 kg to 20 tonnes




Product Code	TR.5PBD	TR1PBD	TR2PBD	TR3PBD	TR5PBD	TR10PBD
Safe Working Load	500kg	1 t	2 t	3 t	5 t	10 t
Adjustable Beam Width mm	64 - 152	64 - 210	88 - 210	102 - 210	114 - 210	125 - 210
Clearance Dimensions	A	254	318	335	357	405
	B	216	260	300	345	395
	C	195	239	286	336	393
	H	110	135	161	185	220
Min. Radius Curve	m	.9	1.0	1.1	1.3	1.4
Net Weight	kg	8	14	21	36	51

- Lightweight robust construction
- Super-quick adjustment to any monorail
- Durable baked enamel paint protection
- Precision ball bearing trolley wheels

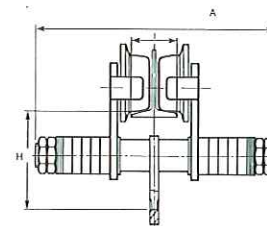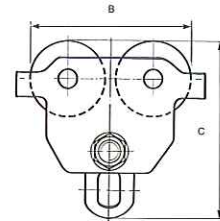

## GEARED GIRDER TROLLEYS

- Capacities 500 kg to 20 tonnes

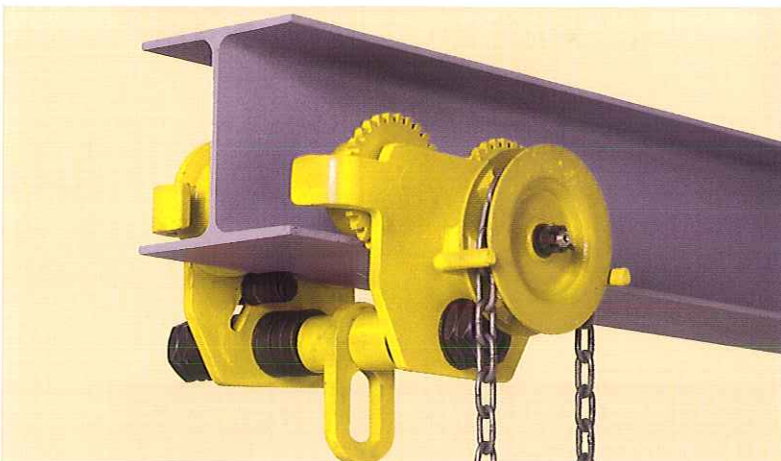

Product Code	TR1GBD	TR2GBD	TR3GBD	TR5GBD	TR10GBD
Safe Working Load	1 t	2 t	3 t	5 t	10 t
Adjustable Beam Width mm	64 - 210	88 - 210	102 - 210	114 - 210	125 - 210
Clearance Dimensions	A	380	390	513	430
	B	260	300	345	395
	C	239	286	336	393
	H	135	161	188	220
Min. Radius Curve	m	1.0	1.1	1.3	1.4
Net Weight	kg	18	27	43	60

- Lightweight robust construction
- Super-quick adjustment to any monorail
- Durable baked enamel paint protection
- Precision ball bearing trolley wheels

