



SIVACON, side panel, flat, IP40, H: 2200 mm, W: 600 mm, RAL 7035

Model			
product brand name		SIVACON	
product designation		Side panel/rear panel	
design of the product		Flat	
design of the surface		Powder-coated	
design of the product EMC version		No	
Protection class			
protection class IP		IP40	
Appearance			
RAL color number		RAL 7035	
color		light grey	
Product details			
product component			
• cable entry		No	
• lock		No	
Mechanical Design			
height		2 200 mm	
width		600 mm	
depth		600 mm	
material		steel	
Approvals Certificates			
General Product Approval		EMV	Test Certificates
		 EG-Konf.	 UL
			 RCM
		Type Test Certificates/Test Report	
Marine / Shipping		other	
 ABS	 DNV	 LRS	 PRS
		Confirmation	Miscellaneous
Environment	Industrial Communication		



Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1260-2UW63-1C>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1260-2UW63-1C>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1260-2UW63-1C

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

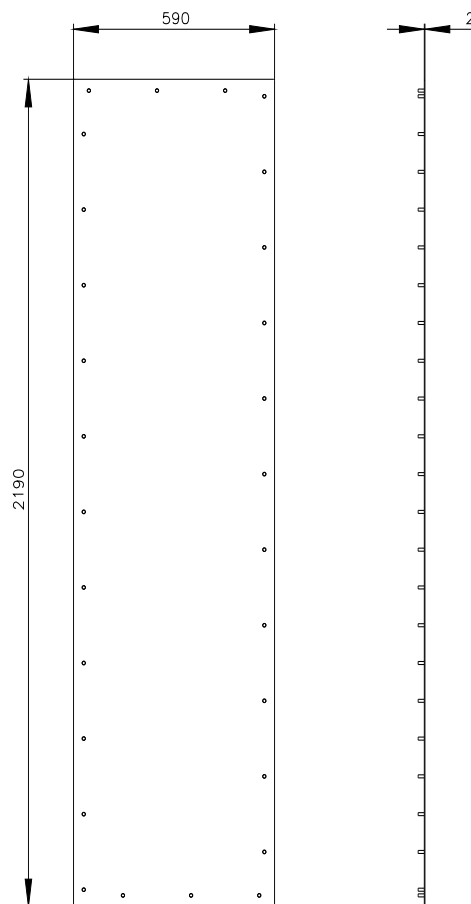

last modified:

2/12/2021 

