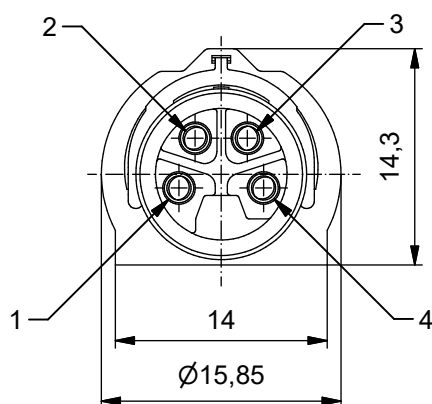
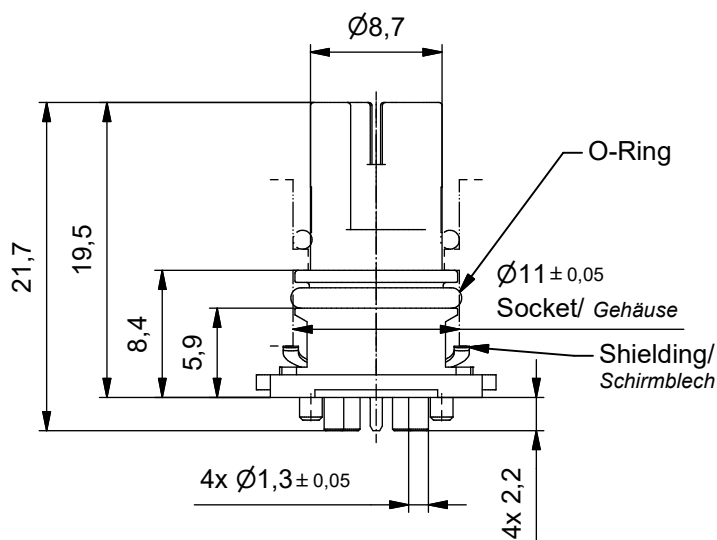


Tape & Reel -
parts with adhesive
pad Ø11mm
Artikel mit
Klebeпад Ø11mm

Technical specification/

Technische Daten:

Rated Voltage/ Bemessungsspannung: IEC 61076-2-111	63 V AC / 63 V DC
Current rating/ Strombelastbarkeit: IEC 61076-2-111	16 A / 40 °C
Insulation resistance/ Isolationswiderstand: IEC 60512	>=100 MΩ
Pollution degree/ Verschmutzungsgrad: IEC 60664-1	3/2
Degree of protection/ Schutzart: IEC 60529	IP 67, in mated condition/ im verschraubten Zustand
Temperature range/ Umgebungstemperatur:	-40 °C ... +105 °C
Mating cycles/ Steckzyklen: IEC 60512-9a	>=100


Materials/

Werkstoffe:


Contact/ Kontakt:	CuZn, Ni b / Au 0,2 gal.
Contact carrier/ Kontaktträger:	PA, UL 94 V-0
Sealing/ Dichtung:	FKM
Shielding/ Schirmblech:	CuSn, Ni / sel. Sn

Suitable for reflow soldering
max. 60s / 250°C
geeignet für Reflow Lötprozess
max. 60s / 250°C

Top view
Layout PCB/
Leiterplatte

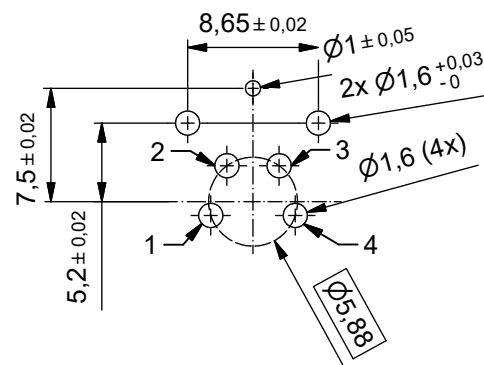

Part no packing unit Tape & Reel/ Art.-Nr. Verpackungseinheit Rolle:	Part no. packing unit in bulk/ Art.-Nr. Verpackungseinheit lose:	Description/ Beschreibung:	Pos/ Pol:
43-04213TR	43-04213	SAL- 12LS - IKO4 / THR	4

 

dim. in mm

general tolerance/
Allgemeintoleranz:

0	± 0,50 mm
0,0	± 0,25 mm
0,00	± 0,10 mm
*	± 1,5°

drawn/
gez.

Date/Datum

Name

appd./
gepr.

01.02.2021

Fischer

Female socket M12x1 L-coded THR 4pos.
shielded
Flanschcupplung M12x1 L-Codiert THR 4pol
geschirmt

Index: b Ä21-0446 09.12.21 ABL

scale/Maßstab:

CONEC®

dwg no /
Z.-nr.:

43K1A5260

DIN-
A4

RoHS & REACH compliant/konform

see table

1 / 1