

CA-12P2N129007 - Coupler connector



1622219

<https://www.phoenixcontact.com/in/products/1622219>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Coupler connector, series: CA, straight, shielded: yes, for standard and SPEEDCON interlock, No. of pos.: 12, Direction of rotation: Counter direction, contact connection type: Pin, Solder connection, cable diameter range: 6 mm ... 10 mm, coding: N, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1244548

Commercial data

Item number	1622219
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	*****
Product key	ABRAEG
GTIN	4055626022475
Weight per piece (including packing)	98.8 g
Weight per piece (excluding packing)	98.8 g
Customs tariff number	85366990
Country of origin	DE

CA-12P2N129007 - Coupler connector



1622219

<https://www.phoenixcontact.com/in/products/1622219>

Technical data

Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

Connector

Insulating body

Coding	N
Insulation body material	PBT
Contact material	CuZn
Contact surface material	Ni/Au
Insertion/withdrawal cycles	100
Connection method	Solder connection
Contact switching type	Pin
Application	Signal
Number of positions	12
Direction of rotation	Counter direction
Connection profile	12
Contact diameter	1 mm
Litz wire cross-section Power contacts min.	0.08 mm ²
Litz wire cross-section Power contacts max.	1 mm ²
Rated current Power contacts	8 A
Rated voltage	48 V AC 74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

Housing

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Type of locking	for standard and SPEEDCON interlock
Pg screw connection	none
Degree of protection (plugged in)	IP67
Thread type	M23

Seal

External cable diameter	6 mm ... 10 mm
Seal material	NBR

CA-12P2N129007 - Coupler connector


1622219

<https://www.phoenixcontact.com/in/products/1622219>



Drawings

Schematic diagram

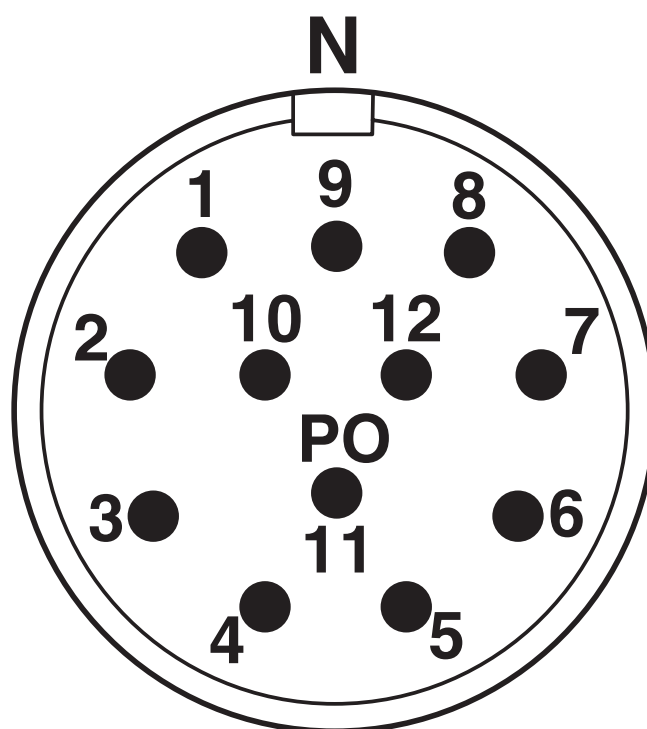

Contact chamber numbering (view of plug-in side), pin counter direction

CA-12P2N129007 - Coupler connector



1622219

<https://www.phoenixcontact.com/in/products/1622219>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1622219>

cUL Recognized Approval ID: E335019-20141210				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	48 V	6 A	18	-

UL Recognized Approval ID: E335019-20141210				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	48 V	8 A	18	-

cULus Recognized				
------------------	--	--	--	--

CA-12P2N129007 - Coupler connector



1622219

<https://www.phoenixcontact.com/in/products/1622219>

Classifications

ECLASS

ECLASS-11.0	27440102
ECLASS-12.0	27440116
ECLASS-13.0	27440116

ETIM

ETIM 9.0	EC002635
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

CA-12P2N129007 - Coupler connector



1622219

<https://www.phoenixcontact.com/in/products/1622219>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	34a227cf-07d0-43ee-9c3b-e53a5ccac8eb

CA-12P2N129007 - Coupler connector



1622219

<https://www.phoenixcontact.com/in/products/1622219>

Accessories

SF-Z0019 - Protective cap

1607449

<https://www.phoenixcontact.com/in/products/1607449>



Plastic protection cap, with eye, IP40 for connectors with M23 external thread, RF, SF series

RC-Z2469 - Protective cap

1611797

<https://www.phoenixcontact.com/in/products/1611797>



Plastic protection cap, antistatic, for RF, SF, CA, RC series connectors, with M23 external thread

CA-12P2N129007 - Coupler connector

1622219

<https://www.phoenixcontact.com/in/products/1622219>




RF-Z0014 - Color coding

1620588

<https://www.phoenixcontact.com/in/products/1620588>

Color coding, color: green

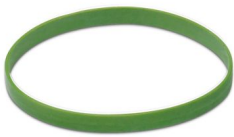

RF-Z0015 - Color coding

1620592

<https://www.phoenixcontact.com/in/products/1620592>

Color coding, color: orange



CA-12P2N129007 - Coupler connector

1622219

<https://www.phoenixcontact.com/in/products/1622219>



RF-Z0016 - Color coding

1620593

<https://www.phoenixcontact.com/in/products/1620593>

Color coding, color: black



PROT-M23PRO-OT-IP20 - Plastic protective cap

1055753

<https://www.phoenixcontact.com/in/products/1055753>

Plastic protective cap, M23, series: M23 PRO



Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in