


Features

- Thermoresistances
- Max. operating temperature 400°C
- ½" Fittingnut
- Protection tube Stainless Steel
- Sensor type DIN/EN60751
- Immersion Length 50mm
- PT-1000 Sensor

RS PRO Bayonet Valve Type PT-1000 Thermoresistances With ½" Fittingnut Connector

RS Stock No: 0350372

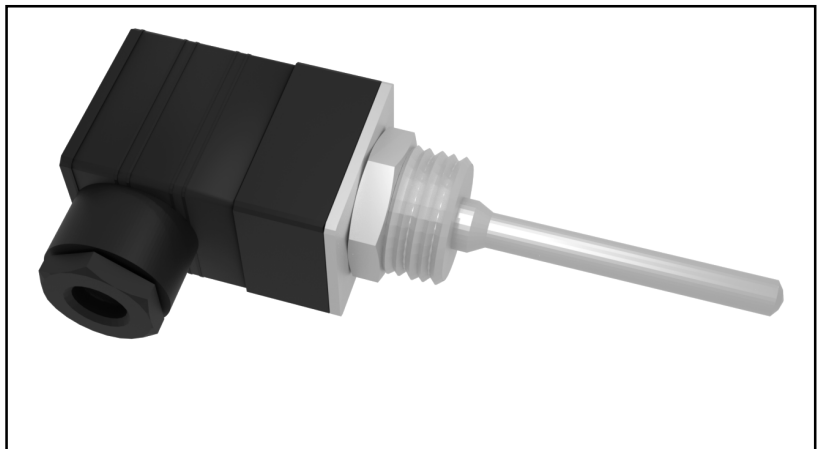

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Standard Bayonet Type PT1000 Thermoresistances Temperature Sensor
Diameter(M): 6mm
Immersion Length(L): 50mm
Applications Fields

- Machinery Manufacturing
- Panel Manufacturing
- Production and Test Equipment
- Food, Chemical, Textile Sectors
- Industrial Control Applications

General Specifications

Max. Operating Temperature	-50 °C / +400 °C
Standard cable types	Fiber glass + fiber glass + braided wire
Sensor type	DIN/EN60751 Class "B" 1xPT-1000
Protection tube material	Stainless Steel
Connector	½" Fittingnut

Mechanical Specifications

Diameter (M)	6mm
Immersion Length (L)	50mm

Electrical Connection

