



## NT 22/1 Ap L


Compact yet unbelievably powerful wet and dry vacuum cleaner entry-level unit. Due to its low weight, the NT 22/1 Ap is ideal for mobile use.



1

### 1 Low weight and compact dimensions

- The machine can be easily and conveniently transported and stored.

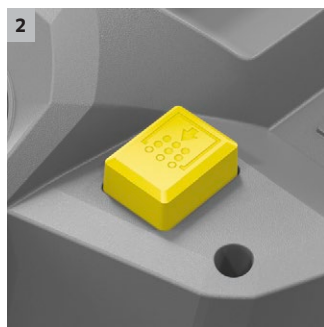

2

### 2 Semi-automatic filter cleaning


- Semi-automatic filter cleaning effectively ensures constantly high suction power.



3

### 3 Moisture-resistant PES cartridge filter

- It is possible to change from wet to dry vacuum cleaning easily without having to dry the PES cartridge filter first.
- Washable PES filter.

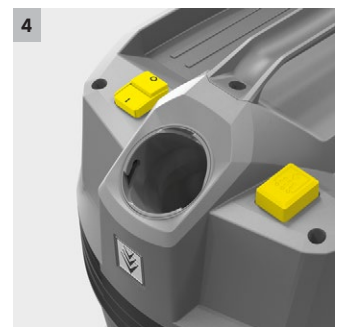

4

### 4 Suction hose connection in the machine head

- Enables the entire container volume to be utilised.
- Save time by not having to empty the container as often.



## NT 22/1 Ap L

- Efficient semi-automatic filter cleaning
- Suction hose port in the head of the machine
- Moisture-resistant PES cartridge filter

### Technical data

<b>Order no.</b>	1.378-600.0	
<b>EAN code</b>	4054278287928	
<b>Supply voltage</b>	<b>Ph / V / Hz</b>	1 / 220 - 240 / 50 - 60
<b>Air flow</b>	<b>l/s</b>	71
<b>Vacuum</b>	<b>mbar / kPa</b>	255 / 25.5
<b>Container content</b>	<b>l</b>	22
<b>Container material</b>	Plastic	
<b>Rated input power</b>	<b>W</b>	1300
<b>Standard nominal width</b>	DN 35	
<b>Cable length</b>	<b>m</b>	6
<b>Sound pressure level</b>	<b>dB(A)</b>	71
<b>Weight</b>	<b>kg</b>	5.7
<b>Weight incl. packaging</b>	<b>kg</b>	9.1
<b>Dimensions (L x W x H)</b>	<b>mm</b>	380 × 370 × 480

### Equipment

<b>Suction hose</b>	<b>m</b>	1.9 / with bend
<b>Suction tube</b>	<b>piece(s) × m</b>	2 × 0.5 / Plastic
<b>Filter bag</b>	<b>piece(s)</b>	1 / Fleece
<b>Wet/dry floor nozzle</b>	<b>mm</b>	300
<b>Crevice nozzle</b>	■	
<b>Cartridge filter</b>	PES	
<b>Filter cleaning</b>	ApClean (semi-automatic filter cleaning)	
<b>Protection class</b>	II	
<b>Stop swivel castor</b>	■	

■ Included in the scope of supply.

# NT 22/1 AP L

## 1.378-600.0



		Order no.	Quantity				Price	Description	
<b>Cartridge filter PES</b>									
Cartridge filter packaged PES	1	2.889-219.0	1 piece(s)					Moisture-resistant PES cartridge filter for wet and dry vacuum cleaning. Dust class L-certified.	■
<b>Fleece filter bags</b>									
Fleece filter bags	2	2.889-217.0	5 piece(s)					Fleece filter bag, tear-resistant, for NT 22/1 Ap and NT 22/1 Ap Te machines. Dust class-L-certified.	□

■ Included in the scope of supply. □ Available accessories.

# NT 22/1 AP L 1.378-600.0

**KÄRCHER**



		Order no.	Quantity	ID	Length	Width	Price	Description	
<b>Bend, plastic</b>									
Elbow, standard	1	2.889-199.0	1 piece(s)	DN 35				Plastic elbow, grey, with C-35 clip system.	■
Bend	2	2.889-148.0	1 piece(s)	DN 35				Ergonomic bend for the new clip system. With airflow control slide, in an antistatic design.	□
Bend Adv, electrically conductive	3	2.889-168.0	1 piece(s)	DN 35				Ergonomic bend for the new clip system. Electrically conductive design. Particularly suited to high concentrations of fine dust.	□
Bend Adv	4	2.889-170.0	1 piece(s)	DN 35				Ergonomic bend for the new clip system.	□
<b>Floor nozzles</b>									
Wet/Dry floor nozzle standard	5	2.889-263.0	1 piece(s)	35		300 mm		Wet/Dry floor nozzle, NW 35, 300 millimetre wide, grey. Incl. brush strips and squeegees. Easy-to-change inserts.	■
Wet and dry floor nozzle Adv	6	2.889-152.0	1 piece(s)	35		360 mm		360 mm wide wet and dry floor nozzle with easy-to-change inserts. Including brush strips and squeegees.	□
<b>Crevice nozzles</b>									
Crevice nozzle DN 35 wet and dry vacuum cleaners 225 mm	7	2.889-159.0	1 piece(s)	35	225 mm			Crevice nozzle with nominal width DN 35 for Kärcher wet and dry vacuum cleaners. Length 225 mm.	■
<b>Suction tubes, plastic</b>									
Suction tube set	8	2.889-218.0	2 piece(s)	35	505 mm			Plastic suction tube set, NW 35, grey, 2 -part, each 0.5 metres.	■
<b>Car cleaning nozzles</b>									
Car nozzle	9	6.906-108.0	1 piece(s)	DN 35		90 mm		Flat angled, convenient, plastic, DN 35 car cleaning nozzle designed for all Kärcher wet and dry vacuum cleaners with bends. Working width: Approx. 90 mm.	□
<b>Rubber suction tools, nose 45°</b>									
Rubber suction tool, nose 45°	10	6.902-104.0	1 piece(s)	35 mm	220 mm			45° rubber suction nozzle (DN 35), oil-resistant and suitable for vacuuming machines. Only for NT vacuum cleaners.	□
	11	6.902-105.0	1 piece(s)	40 mm	220 mm			45° rubber suction nozzle (DN 40), oil-resistant and suitable for vacuuming machines. Only for NT vacuum cleaners.	□
<b>Suction tubes, metal</b>									
Suction tube, chrome-plated	12	6.902-074.0	1 piece(s)	35	505 mm			Suction tube, metal, chrome-plated, NW 35. Length: 0.5 metres.	□

■ Included in the scope of supply. □ Available accessories.

# NT 22/1 AP L 1.378-600.0




		Order no.	Quantity	ID	Length		Price	Description
<b>Complete suction hoses (clip system)</b>								
Suction hose DN 35 clip bayonet 2.5 m wet and dry vacuum cleaners	1	2.889-134.0	1 piece(s)	DN 35	2.5 m			2.5 m suction hose with new bayonet and clip fastener. <input type="checkbox"/>
Electrically conductive suction hose	2	2.889-136.0	1 piece(s)	DN 35	2.5 m			Electrically conductive suction hose with new bayonet and clip fastener. Length: 2.5 m. <input type="checkbox"/>
<b>Extension hoses (clip system)</b>								
Extension hose	3	2.889-145.0	1 piece(s)	DN 35	2.5 m			Extension hose for new clip system ID 35. Length: 2.5 m. <input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

# NT 22/1 AP L

## 1.378-600.0

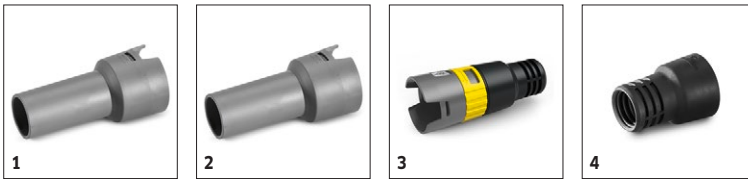

		Order no.	Quantity	ID			Price	Description	
<b>Connection adapter C ID (clip to cone), electrically conductive</b>									
Adapter clip DN 35 on cone DN 35	1	5.407-005.0						Adapter clip system DN 35 for connecting suction tubes and small nozzles to cone DN 35. Perfect for vehicle interior cleaning, even without the connection of other nozzles.	<input type="checkbox"/>
Adapter clip DN 40 to cone DN 40	2	5.407-006.0		DN 40				For connecting small nozzles and suction tubes with cone DN 40: Adapter clip system DN 40. Ideal for vehicle interior cleaning tasks, with no need to connect additional nozzles.	<input type="checkbox"/>
<b>Connection adapter for power tools, clip-on, electrically conductive</b>									
Tool collar DN 35, clip-on	3	2.889-151.0	1 piece(s)	35 mm				Tool adaptor with a rubber fixture and airflow control slide for the new clip system. Suitable for all current electric tools.	<input type="checkbox"/>
<b>Adapter for electric power tools, screwable</b>									
Attachment rubber sleeve	4	5.303-877.0	1 piece(s)	35 mm				Rubber tool socket for screwing onto the suction hose.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

# NT 22/1 AP L

## 1.378-600.0



		Order no.	Quantity	Width			Price	Description	
<b>Other accessories NT</b>									
Drilling dust nozzle	1	2.679-000.0	1 piece(s)					Drilling dust nozzle for dust-free vacuuming of boreholes. Suitable for dry and wet and dry vacuum cleaners from Kärcher.	<input type="checkbox"/>
Adapter clip new on clip old DN 35	2	2.889-312.0						Adapter for connection of hoses of the new accessory system of dry and wet and dry vacuum cleaners to bends or extension hoses of the old system. For nominal width DN 35.	<input type="checkbox"/>
Adapter connection, electroconductive	3	5.031-436.0						Electroconductive, universal adapter for connecting old NT hoses of nominal widths DN 35, 40, 50 to the new accessory system for wet and dry vacuum cleaners from Kärcher.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.