

# Sapphire Total Lite

## High dexterity fully coated nitrile medium cut resistant glove

A great fitting, fully coated glove combining medium cut & excellent grip in oily & wet conditions. Ideal for oily tasks with sharp parts that require great grip.

### Features

- ▲ Cut resistance: Level C / ANSI A3
- ▲ 18g liner make a thin & dexterous glove offering great dexterity
- ▲ Fully coated to protect the hand from oils, hydrocarbons, grease & abrasion, with optimal long lasting grip
- ▲ Extremely comfortable & great fitting
- ▲ Water repellent for working in damp or oily environments
- ▲ Contact heat protection up to 100°C / 212°F for a short period (15 seconds max)
- ▲ Designed for easy movement & continuous wear
- ▲ No irritation by seams in contact with the skin

### Certifications



### Suitable industries & applications

#### Industries

- ▲ Automotive
- ▲ Construction
- ▲ Manufacturing
- ▲ Oil and Gas
- ▲ Utilities
- ▲ Waste and Recycling
- ▲ Highways and Infrastructure

#### Applications

- ▲ Masonry and Brickwork
- ▲ Handling Wet
- ▲ Oily or Greasy Materials
- ▲ Plumbing



#### Europe

sales@globus.com  
+44 (0)161 877 4747  
+44 (0)161 877 4746

#### Middle East & Africa

sales.gcc@globusgroup.com  
+971 4 882 9962  
+971 4 882 9963

#### Americas

salesusa@globusgroup.com  
+1 83 337 54747

The descriptions, characteristics, applications and photos are given for information purposes and do not constitute a contractual commitment. The manufacturer reserves the right to make any modifications it deems necessary.

# Sapphire Total Lite

High dexterity fully coated nitrile medium cut resistant glove

## Product information

<b>Materials</b>	Liner:	18 Gauge Engineered HPPE, Glass Fibre, Nylon, Spandex, HPPE
	Coating:	Sandy Nitrile, Smooth Nitrile
<b>Colour</b>	Black	
<b>Length</b>	130mm	
<b>Cuff Style</b>	Elasticated Knit Wrist	

## Ordering information

<b>XS</b>	SKG00105BB	Items per Pack 10 x Pairs
<b>S</b>	SKG00105BD	
<b>M</b>	SKG00105BF	Items per Case 120 x Pairs
<b>L</b>	SKG00105BH	
<b>XL</b>	SKG00105BJ	
<b>XXL</b>	SKG00105BL	


## Additional information

Certification legend



or click [here](#)

Declaration of conformity

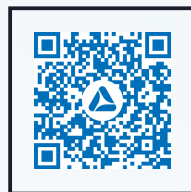

or click [here](#)

View product online



or click [here](#)

### Europe

sales@globus.com  
+44 (0)161 877 4747  
+44 (0)161 877 4746

### Middle East & Africa

sales.gcc@globusgroup.com  
+971 4 882 9962  
+971 4 882 9963

### Americas

salesusa@globusgroup.com  
+1 83 337 54747

**Globus Group**, T2 Trafford Point, Twining Road, Trafford Park, Manchester, M17 1SH, UNITED KINGDOM  
**Globus EMEA FZE**, Jafza One, Tower A, Office 2201, Jebel Ali, PO Box 61195, Dubai, UNITED ARAB EMIRATES  
**Globus Americas LLC**, 45 Rockefeller Plaza, Suite 2000, New York City, New York, 10111, USA

The descriptions, characteristics, applications and photos are given for information purposes and do not constitute a contractual commitment.  
The manufacturer reserves the right to make any modifications it deems necessary.