


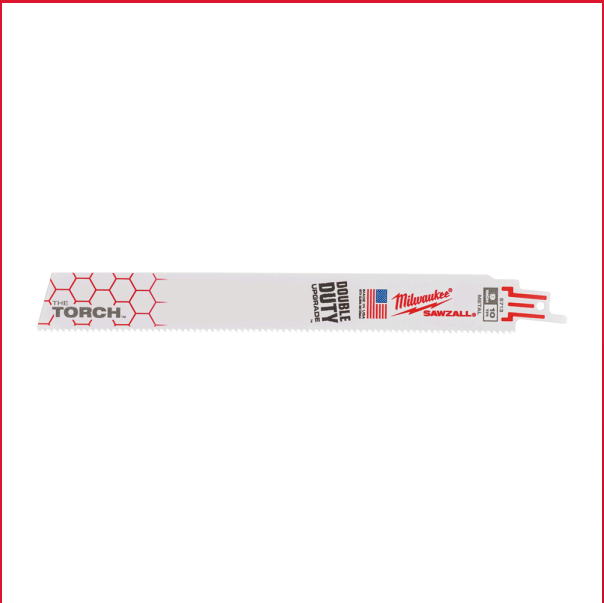

TORCH 230mm x 10 Tpi - 5 pc

METAL: HEAVY DUTY TORCH™ DEMOLITION BLADES

- Strong: Robust 1.06 mm thick body.
- Shatter resistant: The bi-metal blade body will bend and flex but not break.
- Torch: - Thick 1.06 mm robust blade body for precise cuts in sheet metal and pipes.
- 25 mm blade height for improved stability and minimum vibration.



Article Number	48475713
Blade length (mm)	230
Materials suited for	Thick metal > 4 mm Medium metal 1.5 - 4 mm Thin metal 0.5 - 3 mm Stainless steel Non ferrous metal (Cu/Al)
Max. cutting capacity cast iron pipes [mm]	ø 10 - 175
Max. cutting capacity metal pipe	ø 10 - 175
Max. cutting capacity non ferrous metals [mm]	5 - 14
Max. cutting capacity stainless steel [mm]	5 - 10