


705-1257

**Description:** Vernier Height Gauge

**Specification:** 0-300mm/12"

**Resolution:** 0.02mm/0.001"

**Accuracy:**  $\pm 0.03\text{mm}$

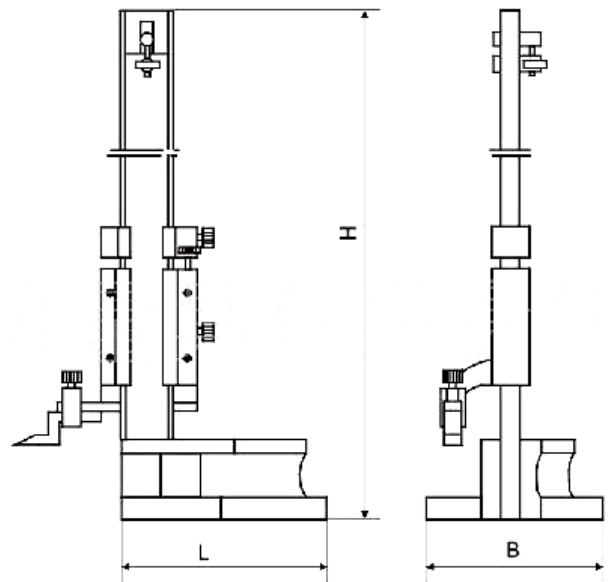

L=135mm B=90mm H=541MM

- Made of stainless steel
- With magnifier reading glass, can help to vernier to read that the number obtain
- The main ruler is adjustable, adjustable opposite zero:00 Of stanza
- With fine adjustment, make the small adjustment convenient
- Carbide tipped scriber
- Can make choice of purchase to revolve tightly solid device, tightly solid more convenient (order note)