

TOREX HOSE

23MTR1901

- Multi-Pocket-Hose mit 4-Wege-Stretch-Einsatz im Schritt und an den Seiten für zusätzliche Bewegungsfreiheit
- Slim fit
- Canvas Stretchgewebe mit Coolmax[®]-Technologie, schnell trocknenden und Feuchtigkeitsableitenden Funktionen
- Vorgeformter Knie
- 2 Seitentaschen
- 1 Zollstocktasche mit Handytasche
- 1 Schenkeltasche mit Kleiner Tasche
- 2 Gesäßtaschen
- 1 Hammerschlaufe
- Auslassbarer Saum
- EN ISO 13688:2013



Size

36 - 38 - 40 - 42 - 44 - 46 - 48 - 50 - 52 - 54 - 56


Color



Zusammensetzung


- Hauptgewebe: 47% Baumwolle - 31% Polyester - 22% T400 Lycra[®] Coolmax[®] 240g/m²
- 4-Wege-Stretch Material: 93% Polyamid - 7% Elasthan

Technologies

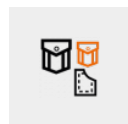

Multipocket

This item has 5 or more pockets for storing different articles and accessories.

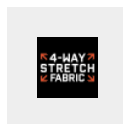

4 way stretch fabric

Four-way (or 4-way) stretch means a fabric stretches and recovers both width and lengthwise




Small size 36

Für diese Hose ist die Größe 36 erhältlich



Extra freedom of movement

This item has been especially developed to ensure an optimal freedom of movement.

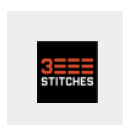

3 stitches

A stitch is a single turn or loop of thread, or yarn.



Phone pouch

This item has a special compartment for carrying a cellular phone.



Extendable Hem

These pants have an extendable hem of 5cm that allows you to set your own ideal length and fit.

Stoffe

- Wasa
- YKK
- Coolmax®

Zertifikate



EN ISO 13688

Allgemeine anforderung für schutzbekleidung.

[Mehr](#)