


Product data sheet

Specifications

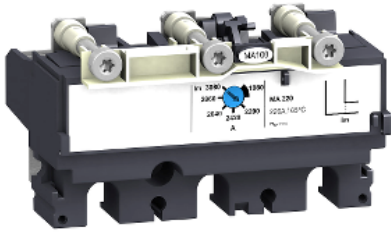

trip unit MA25 for ComPact NSX
100/160 circuit breakers, magnetic,
rating 25 A, 3 poles 3d

LV429122

! Discontinued on: 30 September 2022

! To be discontinued

Important message : This product has been switched to new ComPact range and is no longer commercialized. It will continue to be available until Q4 2022 only limited to specific projects.

Main

Range	ComPact
Range of product	ComPact NSX100...250
Product or component type	Trip unit
Trip unit name	MA
Trip unit technology	Magnetic
Range compatibility	ComPact NSX100 ComPact NSX160
Device application	Motor
Number of poles	3P
Protected poles description	3t
Trip unit protection functions	I
Protection type	I : for short-circuit protection (magnetic)
Trip unit rated current	25 A at 65 °C
[Ue] rated operational voltage	690 V AC 50/60 Hz
Network type	AC
Network frequency	50/60 Hz

Complementary

Instantaneous protection pick-up adjustment type Ii	Adjustable 9 settings
[Ii] instantaneous protection pick-up adjustment range	6...14 x In
Earth-leakage protection	Without

Environment

Standards	UL 508 EN/IEC 60947-2
Product certifications	Marine EAC CCC

Ambient air temperature for operation	-25...70 °C
---------------------------------------	-------------

Ambient air temperature for storage	-50...85 °C
-------------------------------------	-------------

Packing Units

Unit Type of Package 1	PCE
------------------------	-----

Number of Units in Package 1	1
------------------------------	---

Package 1 Weight	398.0 g
------------------	---------

Package 1 Height	6.8 cm
------------------	--------

Package 1 width	10.0 cm
-----------------	---------

Package 1 Length	11.4 cm
------------------	---------

Unit Type of Package 2	S03
------------------------	-----

Number of Units in Package 2	28
------------------------------	----

Package 2 Weight	11.632 kg
------------------	-----------

Package 2 Height	30.0 cm
------------------	---------

Package 2 width	30.0 cm
-----------------	---------

Package 2 Length	40.0 cm
------------------	---------

Offer Sustainability

Sustainable offer status	Green Premium product
--------------------------	-----------------------

REACH Regulation	REACH Declaration
------------------	-----------------------------------

EU RoHS Directive	Compliant EU RoHS Declaration
-------------------	--

Mercury free	Yes
--------------	-----

RoHS exemption information	Yes
----------------------------	---------------------

China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
-----------------------	---

Environmental Disclosure	Product Environmental Profile
--------------------------	---

Circularity Profile	End of Life Information
---------------------	---

WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins
------	---

California proposition 65	WARNING: This product can expose you to chemicals including: DINP, which is known to the State of California to cause cancer, and DIDP, which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
---------------------------	--

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)

LV429122 is replaced by:

1x



Trip unit MA25, ComPacT NSX100/160, 3 poles, magnetic protections, motor protection, 25A rating
C103MA025
