
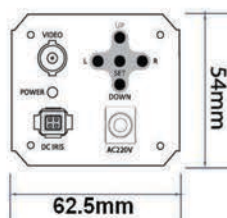


COLOR STANDARD CAMERA

7769380

CAUTION

- Do not open or strike this equipment. Sensitive electronics inside are vulnerable to excessive shock.
- Do not install the equipment near any naked flames or heat sources. Excessive heat could damage this unit.
- Do not cover cloth or to install this unit in poorly ventilated places. This may lead to overheating.
- Do not continue to operate if there appears to be fault.
If the unit ceases to function, contact qualified service personnel for help.
- Do not touch the power connection with wet hands. Risk of short circuit or electric shock.
- Do not damage the power cord or leave it under pressure. Risk of fire or shock circuit.

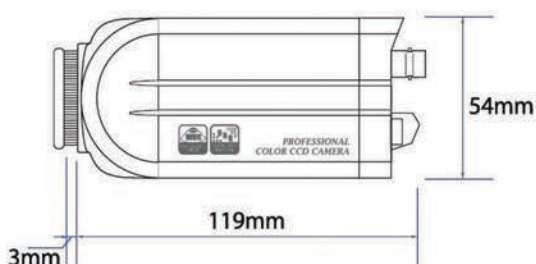

FEATURE

1/3" SONY SUPER HAD II CCD (960H)

HIGH RESOLUTION 700TVL

Min Illumination : 0.0003Lux (F:1.2)

Built-in OSD buttons

Excellent Sensitivity at Night

Dimension(mm) : 62.5 x 54 x (L)119

Power Source : DC12V (6.5V~28V)

WDR, 3D-DNR

P3 RAPTOR PROCESS

SPECIFICATION

| | | | |
|--------------------------------|------------------------|---|------------------------------|
| Image Device | | 1/3" SONY CCD 960H | |
| Total Pixel / Effective Pixels | | 1020(h) X 508(V) / 976 x 494 | 1020(H) X 596(V) / 976 x 582 |
| Scanning System | | 2:1 Interlace | |
| Sync System | | Internal / Line-Lock | |
| Horizontal Resolution | | 700 TV Line | |
| Video Output | | 1.0Vp-p Composite Signal 750ohm) | |
| S/N Ratio | | More than 48dB (AGC OFF) | |
| Min. Illumination | | Color Mode:0.0003(Sens-up Auto,F1.2), B/W mode:0.00003(Sens-up Auto,F1.2) | |
| DSP | | P3 RAPTOR | |
| Electronic Shutter | | 1/60 ~ 1/120,000 | 1/50 ~ 1/120,000 |
| OSD | | Built-In (External 5 buttons) | |
| OSD FUNCTIONS | Exposure | ELC / ALC | |
| | White Balance | ATW(1600°K ~ 11,000°K) / AUTO / ONE PUSH / MANUAL | |
| | Auto Gain Control | OFF / LOW / MIDDLE / HIGH | |
| | Electronic Shutter | 1/60 ~ 1/120,000 | 1/50 ~ 1/120,000 |
| | Backlight Compensation | OFF / WDR / BLC / HSBLC | |
| | Sens-up | OFF / AUTO(X4) / MANUAL(X2 ... X 512) | |
| | Day & Night | DAY / NIGHT / AUTO | |
| | Digital Zoom | ~ x 16 | |
| | Privacy Zone Masking | Retangle: 8 Areas, Circle: 4 Areas, Polygon: 2 Areas | |
| | Motion Detection | 8 Regions | |
| | 3D-DNR | Level 100 Steps | |
| | Defog | ON / OFF | |
| | Digital Effect | OFF / V-Flip / Mirror / Rotate | |
| | MULTI-LANGUAGE | ENG/CHI/KOR/JAP/FRE/ITA/SPA/POR/DUT/GER/POL/RUS/TUR/ARA/HEB | |
| Power Consumption | | DC12V input (6.5V ~ 28V) | |
| Operation Temperature | | -10°C ~ +50°C, RH95% Max (14°F~122°F) | |
| Storage Temperature | | -20°C ~ +60°C, RH95% Max | |
| Weight | | Approx 235 g | |
| Housing | | ALUMINUM | |
| Dimension(mm) | | 62.5 x 54 x (L)119 | |