


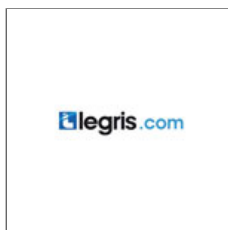

## 3618 - SINGLE BANJO, BSP PARALLEL AND METRIC



<b>maximum working pressure</b>	30 bar 3 MPa 435 psi
<b>working temperature</b>	-25 to 150 °C -13 to 302 °F 248 to 423 °K
<b>vacuum capability</b>	755 mm Hg
<b>body</b>	FDA CHEMICAL NICKEL PLATED BRASS
<b>'O'-rings</b>	FKM
<b>collar</b>	FDA CHEMICAL NICKEL PLATED BRASS
<b>sealing washer</b>	FDA CHEMICAL NICKEL PLATED BRASS
<b>screw</b>	FDA CHEMICAL NICKEL PLATED BRASS

[inch Part numbers](#)
[Convert to inch](#)
[Convert to oz](#)
[Reset Filters](#)

Part Nb	ØD (MM)	C	F (mm)	H (mm)	H1 (mm)	J (mm)	L1 (mm)	L2 (mm)	(kg)
3618 04 10	4	G1/8	13	16.5	7	15	7.5	22	.029
3618 04 19	4	M5x0,8	8	13	6	10	6	18.5	.011
3618 06 10	6	G1/8	13	16.5	7	15	7.5	24	.031
3618 06 13	6	G1/4	17	21	9	18	9	24	.049
3618 06 19	6	M5x0,8	8	13	6	10	5	22.5	.015
3618 08 10	8	G1/8	13	16.5	7	15	7.5	25.5	.033
3618 08 13	8	G1/4	17	21	9	18	9	26.5	.051
3618 10 17	10	G3/8	20	24.5	11	21.5	11	33	.105