

Products

B4MASK series | Double-pole switch 16A quick connection 6.3 black body grey bellow matt rocker



sample image

PRODUCT CODE: B4MASK52N1121000

Wiring diagrams



Terminal type



accessories

Body colour



Actuator colour



Marking



Marking colour



Rating


16 (8) A / 250 VAC
12 (10) A / 250 VAC - 5E4
T120/55 °C

20 A / 125 VAC
 3/4 HP - 125 VAC
 16 A / 250 VAC
 3/4 HP - 250VAC
 T105 °C


Approvals




Dimensions (mm)

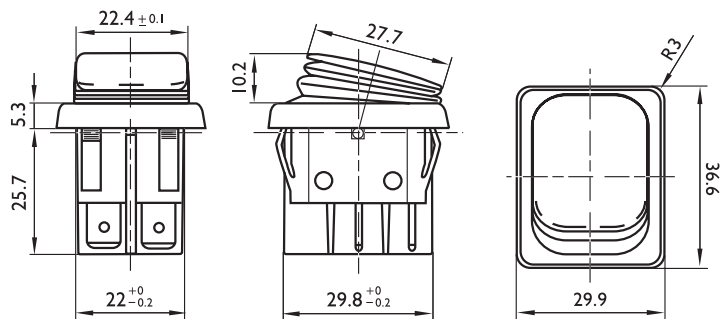

Cut out (mm)

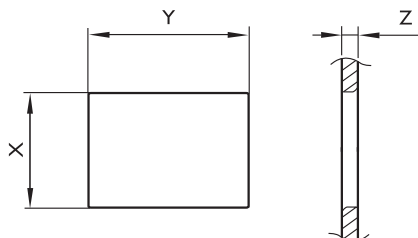

Termination

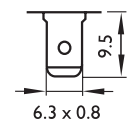

Z	Y	X
0.7-1.25	30.2 +0.1	22.0 +0.2-0
1.25-2.0	30.6 +0.1	22.0 +0.2-0
2.0-3.0	30.8 +0.1	22.0 +0.2-0