


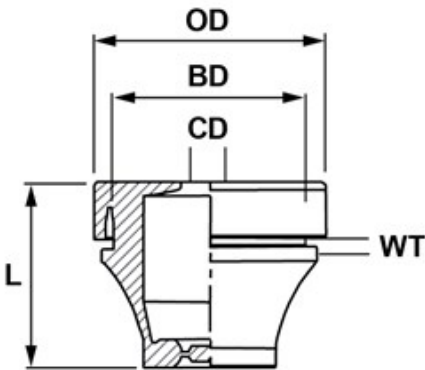

VET M25 SV EPDM

E1458184

VET-GROMMETS, EPDM BLACK, M25, 10-14mm

Product Properties:

Gastight	No
Degree of protection (IP)	IP67
Watertight	Yes
Fire resistant	No
Angle model	No
With strain relief	No
Model	Closed
Material quality	Ethylene-propylene diene monomer rubber (EPDM)
Shrink technique	No
Insert for cable gland	No
Cable entry	Round
Number of cables	1 .
Colour	Black
Surface protection	Untreated
Operating temperature	-40-100 °C
Material	Rubber
Halogen free	Yes

Dimensions:

BD	25.2 mm
CD	10-14 mm
OD	32 mm
L	19.5 mm

WT	1.3-5 mm
MOQ	50 .
Unit	pcs
Bore diameter	25.2 mm
For wall thickness	1.3-5 mm
Suitable for cable diameter	10-14 mm
Thread size (metric)	25 .

Approvals:

Degree of protection (IP)	IP67
---------------------------	------

Compliance:

Conflict Minerals	N/A, Contains no conflict minerals
Extended Minerals	N/A, contains no extended minerals
Iron and Steel Sanction	Compliance
PFAS	No PFAS
POPs	No POPs
REACH	No SVHC (Latest. 21 Jan 2025)
RoHS	RoHS 3 (2015/863)
SCIP	Not Applicable
ECCN (EU)	No CLASS
ECCN (US)	EAR99

Other information:

ETIM-Class	EC000879 - Cable entry sleeve
ETIM-Release	9.0
Trademark	NEMIQ
Product Group	VET-grommets
Search Description	VET-HYLSA, EPDM
Alternative SKU	VETM25SVEPDM
E-no	E1458184

Logistic information:

Barcode	733117610271
Country of origin	CN
E-no	E1458184
Item status	Stock item, normally in stock with reservation for in between sales.
MOQ	50 .
Stock code	VET M25 SV EPDM
Taric code	40169300
Unit	pcs

*We reserve the right to make technical changes and disclaim any typographical errors.

Nelco Contact AB - Daléns Gata 7, 195 61 Arlandastad, Sweden - Tel. +46 (0)8 754 70 40 - order@nelco.se - www.nelco.se