


Fuses 5 x 20

Glass Fuses, slow-blow

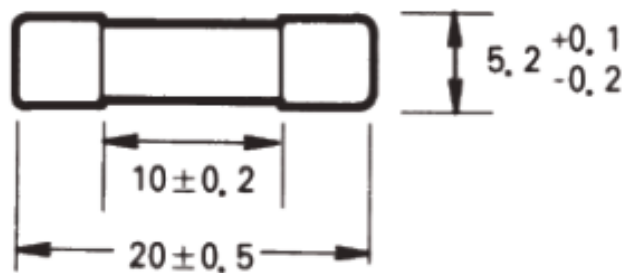

Time delay (T) IEC60127-2/3

Nickel plated end caps

Spiral element or plated solder section for superior characteristics

SPECIFICATION:

Characteristic (time/current)	Slow-blow
Rated voltage	250 VAC/DC
Type of housing/package/case	Glass tube
Dimensions $\varnothing \times L$	5.2 x 20 mm
Breaking capacity	35 A/ 250 V
Approvals	UL

PRODUCT RANGE:

Art. Nr.	Rated current
RND 170-00042	0.05 A
RND 170-00039	0.063 A
RND 170-00037	0.08 A
RND 170-00054	0.1 A
RND 170-00053	0.125 A
RND 170-00052	0.16 A
RND 170-00049	0.2 A
RND 170-00048	0.25 A
RND 170-00046	0.315 A
RND 170-00044	0.4 A
RND 170-00041	0.5 A
RND 170-00038	0.63 A
RND 170-00036	0.8 A
RND 170-00057	1 A
RND 170-00056	1.25 A
RND 170-00055	1.6 A
RND 170-00051	2 A
RND 170-00050	2.5 A
RND 170-00047	3.15 A
RND 170-00045	4 A
RND 170-00043	5 A
RND 170-00040	6.3 A
RND 170-00002	10 A