


KEMET Part Number: SSHB10HS-R06330
(UALSB1SR063300)

KEMET, SSHB10HS, AC Line Filters, Dual Mode, 0.033 H

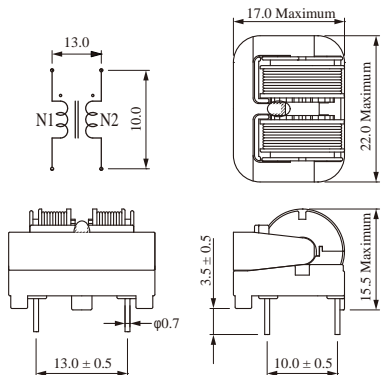

Dimensions

L	22mm MAX
T	17mm MAX
H	15.5mm MAX
LL	3.5mm +/-0.5mm
S	13mm +/-0.5mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	300
Weight:	10 g

General Information

Series:	SSHB10HS
Style:	Through-Hole
RoHS:	Yes
Notes:	Marking: R06 Lot No.
Miscellaneous:	Temperature Rise Maximum: 50 K

Specifications

Voltage AC:	250 VAC
Inductance:	33 mH (10 kHz)
Current:	600 mA
Temperature Range:	-25/+120°C
DC Resistance:	1.17 Ohms