


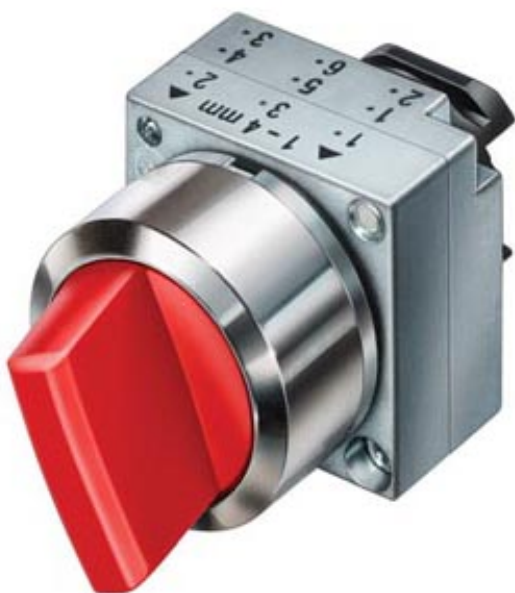

22MM METAL ROUND ACTUATOR: SELECTOR SWITCH
LATCHING 3 SWITCH POSITIONS I-O-II NON-
ILLUMINATED WITH HOLDER WHITE

Actuator:

Design of the operating mechanism

selector switch heavy-duty version with 3 switch positions

Shape / of the activation element

round

Manner of function / of the activation element

- arresting lock
- tentative

Yes
No

Outer diameter / of the activation element

mm 28.5

Material / of the activation element

plastic

Button:

Color / of the button

white

Front ring:

Material / of the front ring

metal

Color / of the front ring

silver

General technical details:

Design of the product

heavy-duty version with 3 switch positions

Number of control points

1

Number of indicator lights / installable

0

Number of switching positions

3

Product extension / optional / fluorescent materials		No
Product function / emergency-OFF function		No
Type of unlocking device		rotate-to-unlatch mechanism
Resistance against shock • for devices without incandescent lamp / according to IEC 60068-2-27		<= 50g
Operating cycles / maximum	1/h	1,000
Resistance against vibration / according to IEC 60068-2-6		20 ... 200 Hz: 5g
Mechanical operating cycles as operating time / typical		300,000
Item designation • according to DIN 40719 extendable after IEC 204-2 / according to IEC 750 • according to DIN EN 61346-2		S S

Auxiliary Contacts:

Number of NC contacts / for auxiliary contact		0
Number of NO contacts / for auxiliary contact		0
Number of change-over switches / for auxiliary contact		0

Installation/mounting/dimensions:


Product component / front ring		Yes
Material / of the housing		metal
Type of mounting		front mounting
Installation width	mm	22
Shape / of the installation hole		round
Mounting diameter	mm	22
Height	mm	30
Width	mm	30
Depth	mm	53
Tightening torque / of the screws in the holder / maximum	N·m	1

Ambient conditions:

Ambient temperature • during the operating phase • during storage	°C °C	70 ... -25 -40 ... 80
Protection class IP		IP67
Climatic class / according to DIN EN ISO 6270-2		KTW24

Certificates/approvals:

General Product Approval		Test Certificates	
	ROSTEST		Manufacturer
Shipping Approval			
ABS			PRS
			
other			
Manufacturer			
Further information:			
Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/industrial-controls/catalogs			
Industry Mall (Online ordering system) http://www.siemens.com/industrial-controls/mall			
CAX-Online-Generator http://www.siemens.com/cax			
Service&Support (Manuals, Certificates, Characteristics, FAQs,...) http://support.automation.siemens.com/WW/view/en/3SB3500-2SA61/all			
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...) http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3SB3500-2SA61			

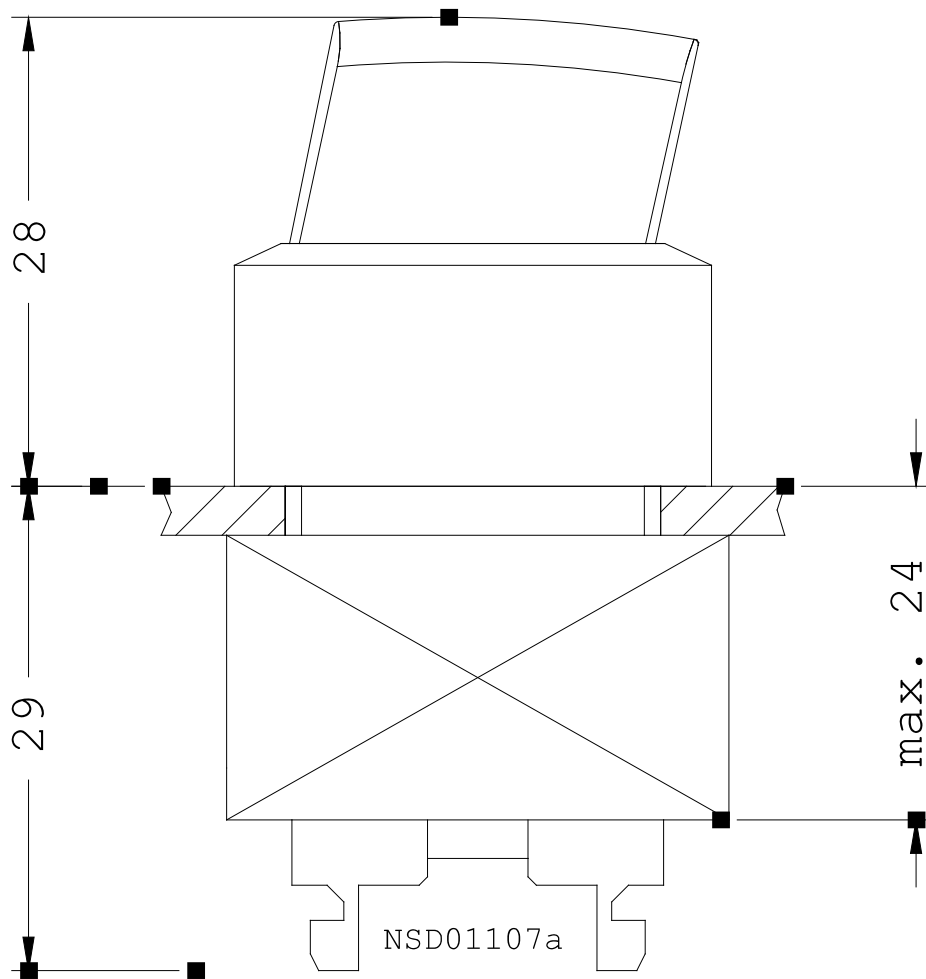

last change:

Sep 6, 2010