

Accessory, Helawrap, black, 50pcs. (HWBASEA)

Art.-No. 161-64013 | HWBASEA-PA66HIRHS-BK | 



- Mounting plates can be fixed with screws, cable ties or adhesive
- Can be used to mount any size HWClip

HF ✓

RoHS ✓

More products in this product group:

[Accessories for retaining Helawrap Open Cable Cover >](#)

This product is part of:




[Samples Helawrap Accessories](#)

Application	To complete the Helawrap cable management system various Helawrap Clips in compatible sizes are available. The mounting clips can be combined and adjusted individually. Attached to a mounting base the assembly can be screw mounted or directly stuck to the surface.
Colour	Black (BK)
Fixation Method	screw-hole
Material	Polyamide 6.6, high impact modified, heat stabilised (PA66HIRHS)
PART DESCRIPTION	HWBASEA-PA66HIRHS-BK
Pack Content	50 pcs.
Package Content packed in	pack
Product Family	HWBase
Product Group	Acessories for retaining Helawrap Open Cable Cover
Type	HWBASEA

Product Dimensions

Length (L)	38 mm
Width (W)	38 mm

Adhesive	Acrylate with base of polyurethane foam
CE Certification	No
CSA Certified	No
ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 HB
Halogen-free	Yes
Hazardous Goods	No
Melting Point	+284 °F (+140 °C)
Operating Temperature	-40 °C to +105 °C
ROHS compliant	Yes
Specifications	HF✓RoHS✓
UL Listed (US and Canada)	No
UL Listed (US and Canada)	No
UL Recognized (US and Canada)	No
UL Recognized (US)	No
UV-Stabilised	No

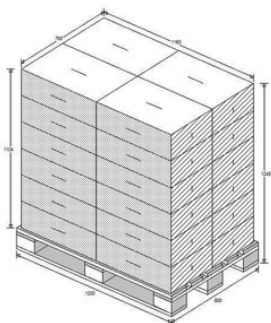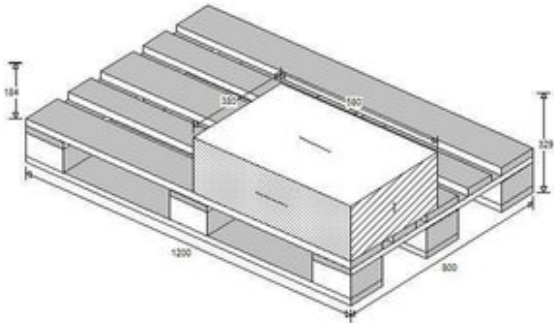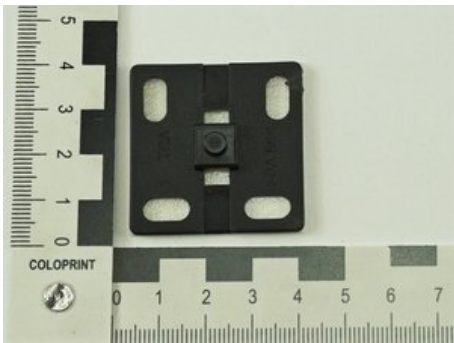

GTIN-13 / EAN	4031026575506
Packaging 1 - Height (m)	0.15 m
Packaging 1 - Length (m)	0.3 m
Packaging 1 - Qty	50
Packaging 1 - Type	bag
Packaging 1 - Volume (m³)	0.0117 m³
Packaging 1 - Weight (kg)	0.204462 kg
Packaging 1 - Width (m)	0.26 m
Packaging 3 - Height (m)	0.184 m
Packaging 3 - Length (m)	0.58 m
Packaging 3 - Qty	2000
Packaging 3 - Type	box
Packaging 3 - Volume (m³)	0.0406 m³
Packaging 3 - Weight (kg)	8.77848 kg
Packaging 3 - Width (m)	0.38 m
Packaging 4 - Height (m)	1.248 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	48000
Packaging 4 - Type	pallet
Packaging 4 - Volume (m³)	1.198 m³

More Information

UNSPSC Key	39131604
------------	----------