


1748-SC

Self-locking stainless steel cable ties, black polyester coating

CE

Material: stainless steel AISI 304 + polyester
 Locking device: roller ball type
 Self-extinguishing class: non-flammable
 Plenum rating: AH-1
 UV resistance: excellent
 Working temperature: -60 °C ÷ +300 °C
 Minimum installation temperature: -60 °C
 Resistance to chemicals: excellent
 Reference standards: EN 62275:2015-02
 Classification: type 2 (EN); type 2 (UL)

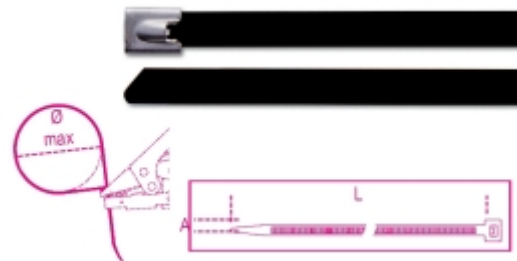

	art.	A mm	L mm	ØMAX mm	Trazione N
BMSC1345	BMSC1345	4.6	125	38	450
BMSC2045	BMSC2045	4.6	200	61.9	450
BMSC2079	BMSC2079	7.9	200	61.9	800
BMSC3045	BMSC3045	4.6	290	90.6	450
BMSC3079	BMSC3079	7.9	300	90.6	800
BMSC3745	BMSC3745	4.6	360	112.8	450
BMSC3779	BMSC3779	7.9	360	112.8	800
BMSC5079	BMSC5079	7.9	520	163.8	800
BMSC5245	BMSC5245	4.6	520	163.8	450
BMSC6845	BMSC6845	4.6	680	214.8	450
BMSC6879	BMSC6879	7.9	680	214.8	800
BMSC8445	BMSC8445	4.6	840	265.7	450
BMSC8479	BMSC8479	7.9	840	265.7	800