



Plate VABF-XA-12-M2-QX

Part number: 8191794

FESTO

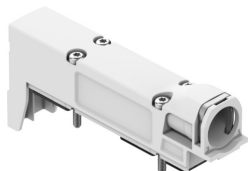

 [General operating condition](#)

Data sheet

Feature	Value
Size of pack	1
Flow direction	Reversible
Compatible with	Valve terminal VTUX-A-P Valve terminal VTUX-A-S
Operating pressure	-0.1 MPa ... 0.7 MPa
Operating pressure	-1 bar ... 7 bar
Suitability for vacuum	yes
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C ... 70 °C
Nominal torque	0.8 Nm
Tolerance for nominal tightening torque	± 10%
Product weight	34.7 g
Type of mounting	Threaded
Pneumatic connection 3/5 combined	For 15 mm cartridge
Note on materials	RoHS-compliant
Material seals	NBR
Material housing	PA-reinforced
Material clip	High-alloy stainless steel
Material screws	Stainless steel