

FEATURES

- Non-toxic
- Accept dividers to further organise contents
- Ergonomic and durable design
- Resistant to most chemicals, including oil and acids
- Lifting handle on larger bins
- Moulded in card holder

RS PRO PP Storage Bin Storage Bin, 180mm x 239mm, Red

RS Stock No.: 390-3514



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

From RS Pro range of high-quality plastic storage bins made from robust polypropylene designed for simple and effective small parts organisation and storage in the workplace and in the home. These storage bins are stackable and can be stacked on top of one another to provide both a space saving solution to your storage needs and ease of handling

[390-3299](#) is a 103 x 100 x 50mm Red Stack & Nest Bin [390-3328](#) is a 103 x 100 x 50mm Blue Stack & Nest Bin

[390-3356](#) is a 172 x 109 x 80mm Red Stack & Nest Bin

[390-3384](#) is a 172 x 109 x 80mm Blue Stack & Nest Bin

[390-3407](#) is a 250 x 179 x 130mm Red Stack & Nest Bin

[390-3435](#) is a 250 x 179 x 130mm Blue Stack & Nest Bin

[390-3457](#) is a 349 x 239 x 130mm Red Stack & Nest Bin

[390-3491](#) is a 349 x 239 x 130mm Blue Stack & Nest Bin

[390-3558](#) is a 349 x 239 x 180mm Blue Stack & Nest Bin

[390-3514](#) is a 349 x 239 x 180mm Red Stack & Nest Bin

[390-3570](#) is a 470 x 385.5 x 180mm Red Stack & Nest Bin

[390-3609](#) is a 470 x 385.5 x 180mm Blue Stack & Nest Bin

[390-3659](#) is a 510 x 335 x 246mm Blue Stack & Nest Bin

[390-3621](#) is a 510 x 335 x 246mm Red Stack & Nest Bin

General Specifications

Material	PP
Colour	Red
Size	Size 5
Application	Home, Office ,Warehouse ,Laboratory, Hospital, Garage

Mechanical Specifications


Volume	9.74 litres
Maximum Container Stack Height	4mm
Maximum Stack Load Capacity	60kg
Weight	30kg

External dimensions		
Dimension	349mm x 239mm x 180mm	
Depth	349mm	(Overall)
Width	239mm	(Overall)
Height	180mm	(Overall)
Base Length	303mm	(Overall)

Internal dimensions	
Dimension	332mm x 154mm x 174mm
Depth	332mm
Width	154mm
Height	174mm
Base Length	295mm

Operation Environment Specifications

Operating Temperature Range	-15°C to 50°C
-----------------------------	---------------

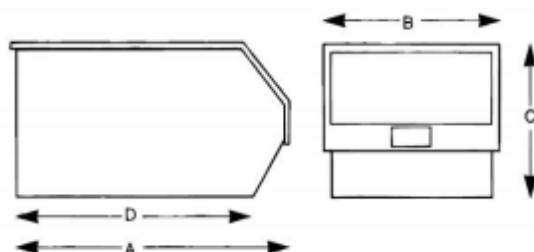

All Dimensions in mm	SIZE 1	SIZE 2	SIZE 3	SIZE 4	SIZE 5	SIZE 6	SIZE 7
(A) Overall Length	103	172	250	349	349	385.5	510
(B) Overall Width	100	109	179	239	239	470	335
(C) Overall Height	50	80	130	130	180	180	246
(D) Overall Base Length	83	135	205	313	303	316	410
(A) Internal Length	95	160	234	332	332	326	449
(B) Internal Width	76	74	116	154	154	362	214
(C) Internal Height	47	77	128	128	174	173	244
(D) Internal Base Length	80	135	195	300	295	275	370
Volume (Litres)	0.37	0.9	3.87	7.49	9.74	21.01	27.11
Maximum Container Stack Height (See Details Opposite)	7	5	4	4	4	5	4
Maximum Stack Load Capacity (Kgs)	8	8	25	40	60	80	75
Dividers (Front to Back)	-	-	-	400-9073	400-9095	400-8373	400-9089
Dividers (Left to Right)	-	-	400-8339	400-8367	400-8351	-	400-8345