



Brand of NTN corporation


## Technical data

### BBET16UU-OP

Super ball bushings



#### VISUAL (S)

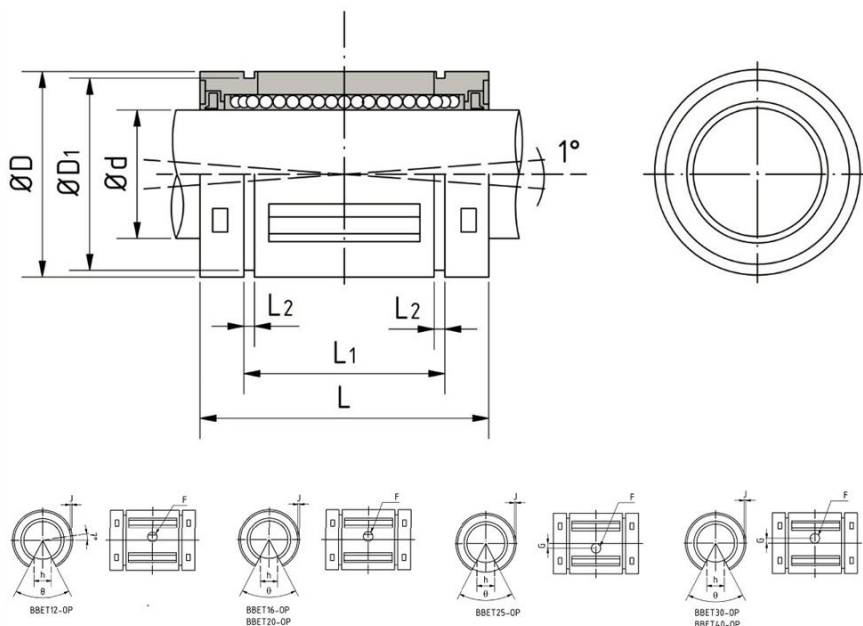

#### PRODUCT DEFINITION

|                                           |                             |
|-------------------------------------------|-----------------------------|
| Brand                                     | SNR                         |
| Design type                               | BBET                        |
| Ball bushings category                    | Super ball bushings, closed |
| Standard                                  | ISO dimension               |
| Number of seals                           | 2                           |
| Material outer cylinder or steel segments | 100Cr6                      |
| Material Cage                             | PA                          |
| Initial greasing                          | Non/No                      |
| Re-lubricable                             | Oui/Yes                     |



#### NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

| PRODUCT DEFINITION              |              |
|---------------------------------|--------------|
| Fixing hole                     | Oui/Yes      |
| d - Internal diameter           | 16 mm        |
| d - Internal diameter tolerance | 0,009/-0,001 |
| D - External diameter           | 26 mm        |
| L - Length                      | 36 mm        |
| L - Length tolerance            | 0,2/-0,2     |
| L1                              | 24,9 mm      |
| L1 tolerance                    | 0/-0,2       |
| D1 - Diameter                   | 24,9 mm      |
| L2                              | 1,3 mm       |
| E                               | 9 mm         |
| Alpha                           | 68 °         |
| Diameter F H11                  | 3 mm         |
| J                               | 1 mm         |
| Number of ball rows             | 4            |
| Mass                            | 0,035 kg     |

| PRODUCT PERFORMANCE |         |
|---------------------|---------|
| Cmin                | 1,25 kN |
| Cmax                | 1,25 kN |
| C0min               | 1,55 kN |
| C0max               | 1,55 kN |
| Crev for OP         | 675     |
| C0rev for OP        | 837     |



**PRODUCT PERFORMANCE**

|                                         |        |
|-----------------------------------------|--------|
| <b>Tmin - Min operating temperature</b> | -20 °C |
| <b>Tmax - Max operating temperature</b> | 80 °C  |

**ESHOPDONOTDISPLAY**

|                              |                              |
|------------------------------|------------------------------|
| <b>Reference</b>             | BBET16UU-OP                  |
| <b>Image</b>                 | BBET-OP_1.JPG, BBET-OP_3.JPG |
| <b>Send to Eshop</b>         | Yes                          |
| <b>Send to Paper Catalog</b> | Yes                          |
| <b>Tracepart</b>             | Oui/Yes                      |

